

E10791




Female wirable connectors

SDOGH040MSSFKPG

Article no longer available - archive entry

Alternative articles: E11508
When selecting an alternative article and accessories please note that technical data may differ!

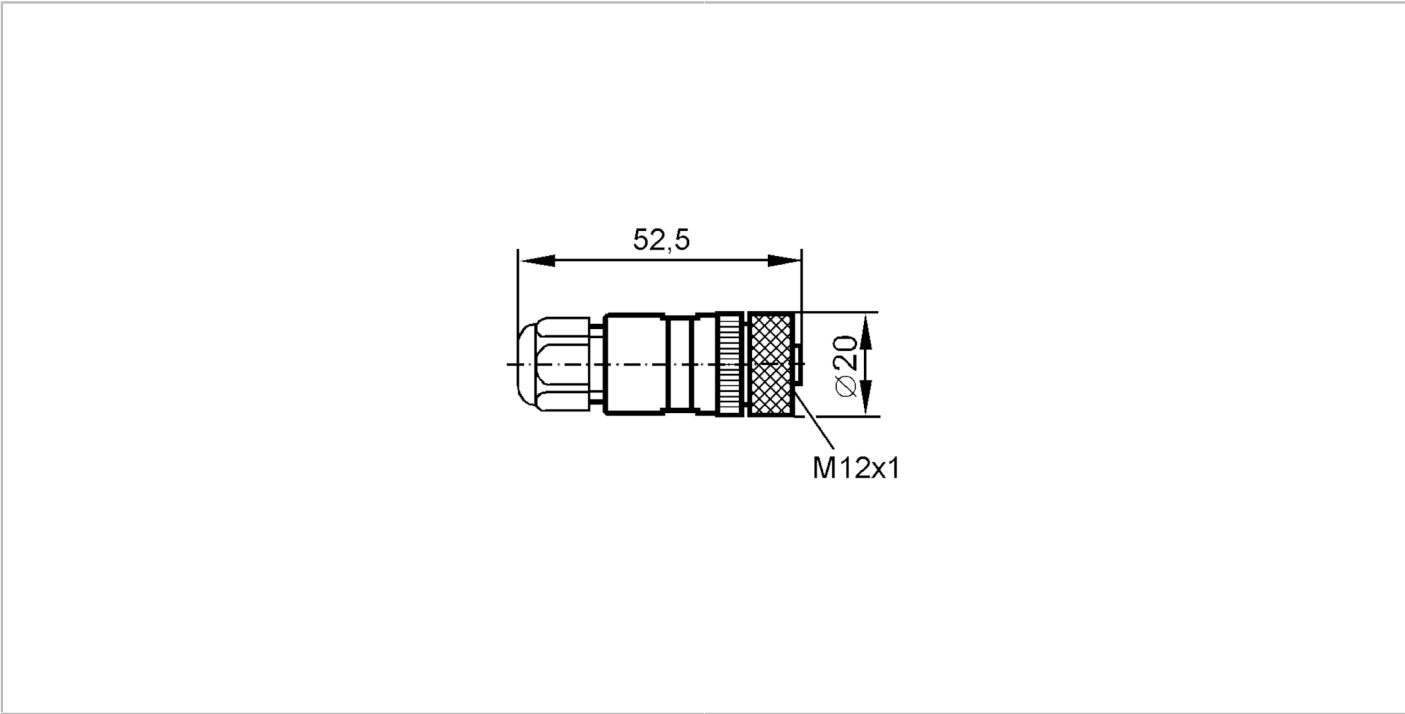

Electrical data		
Frequency AC	[Hz]	47...63
Operating voltage	[V]	< 125 AC / < 150 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	20 x 20 x 52.5
Material		PA
Molded-body material		PA
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10791



Female wirable connectors

SDOGH040MSSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: brass, nickel-plated



Connection

