


E10801



Female cordset

ADOGH040VAS0020E04

Article no longer available - archive entry

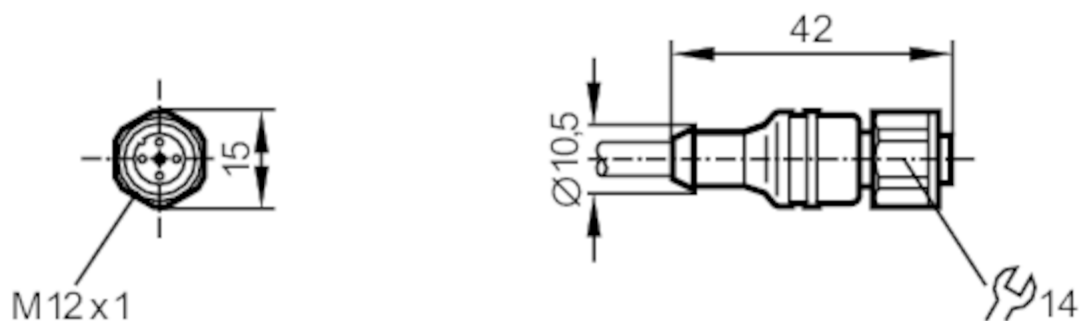

Application

System	gold-plated contacts
--------	----------------------

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
-------------------	-----	---------------------

Operating conditions

Ambient temperature	[°C]	-25...70
Protection		IP 67

Mechanical data

Dimensions	[mm]	15 x 15 x 42
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		stainless steel (1.4404 / 316L)

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E10801



Female cordset


ADOGH040VAS0020E04

Electrical connection


Cable: 20 m, PVC, orange; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated

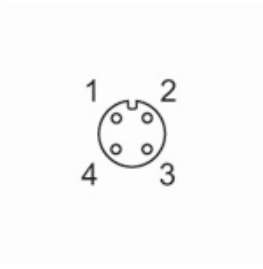

Connection

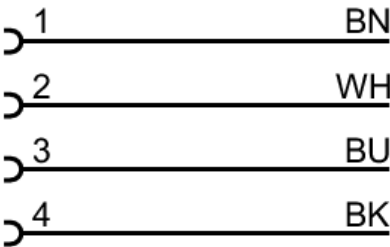

	Core colors :
BK =	black
BN =	brown
BU =	blue
GY =	grey