


E10814



Female cordset

ADOAF032VAS0020A03

Article no longer available - archive entry

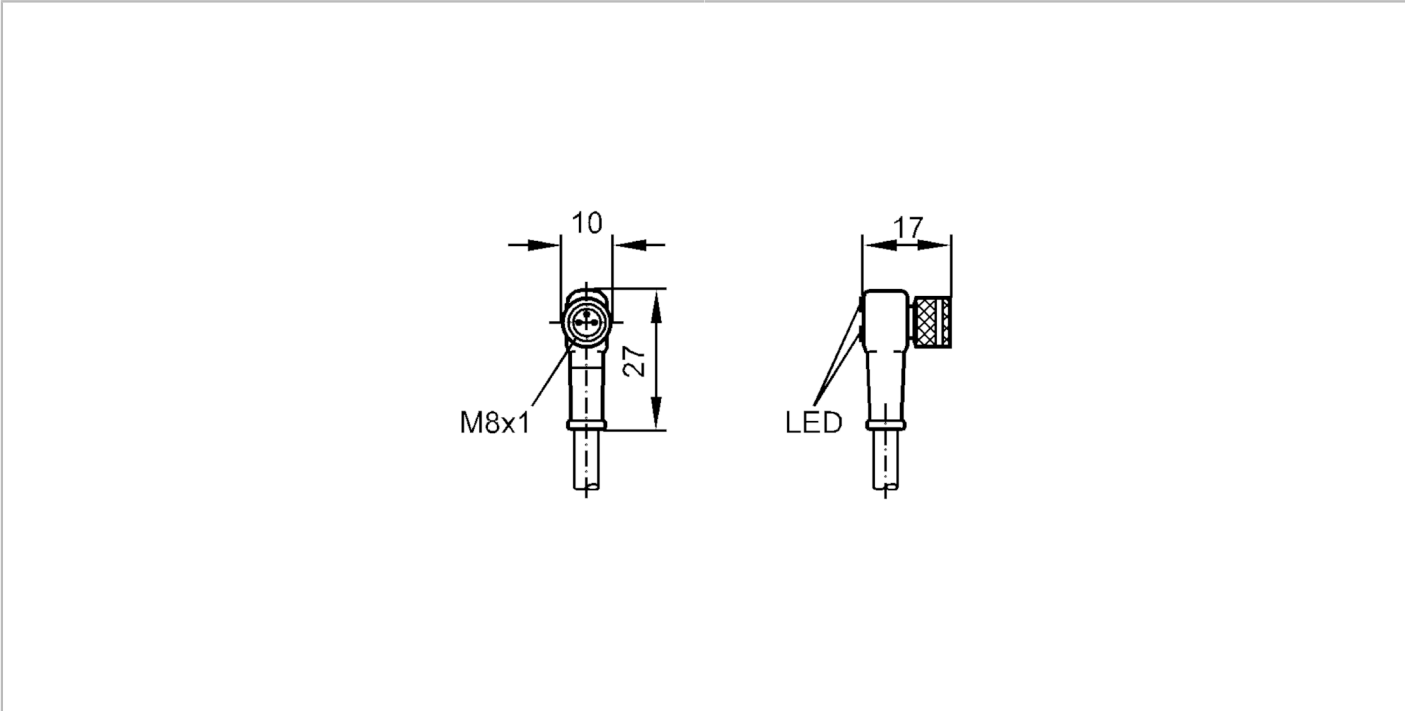

Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Material		PUR
Molded-body material		PUR
Material nut		stainless steel (1.4305 / 303)
Displays / operating elements		
Display	Switching status	1 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10814



Female cordset

ADOAF032VAS0020A03

Electrical connection


Cable: 20 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.25 mm² (128 x Ø 0.05 mm)

Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: stainless steel (1.4305 / 303)



Connection

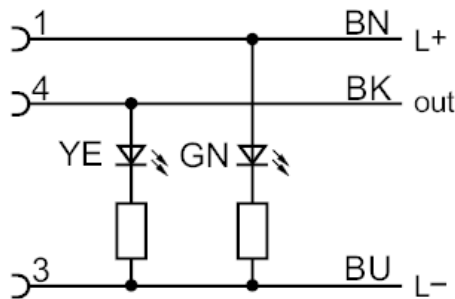

BK = Core colors :
BN = black
BU = brown
BU = blue