


E10815



Connection cable

VDOGH040MSS00,2A03STGX030

Article no longer available - archive entry

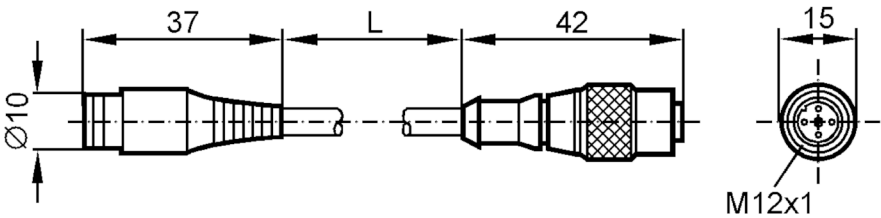

Electrical data

Operating voltage	[V]	10...55 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...70
Protection		IP 65

Mechanical data

Material	TPU (urethane)
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x Torson, straight; Moulded body: TPU (urethane); Locking: brass, nickel-plated



E10815




Connection cable

VDOGH040MSS00,2A03STGX030

Electrical connection

Cable: 0.2 m, PUR / PVC

Connection

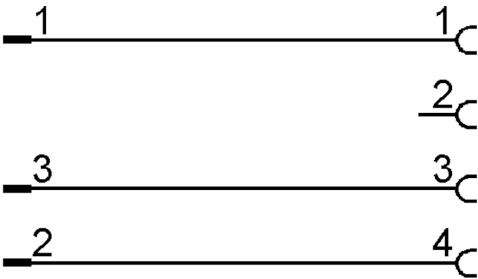

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

