


E10816



Connection cable

VDOAH040MSS00,2A03STGX030

Article no longer available - archive entry

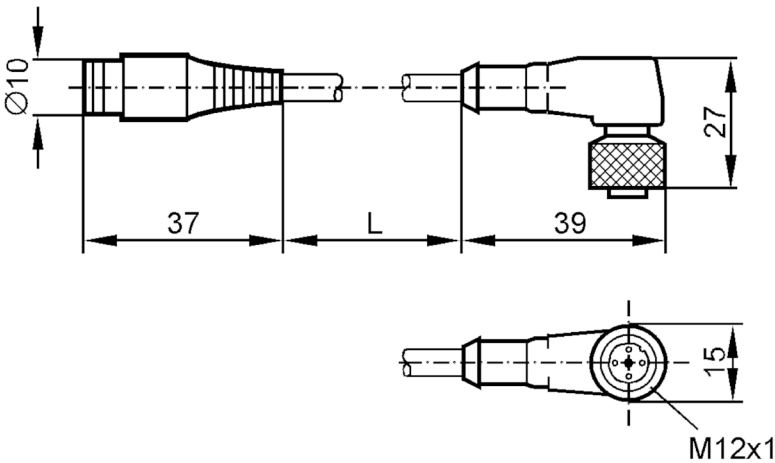

Electrical data		
Operating voltage	[V]	10...55 DC
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 65
Mechanical data		
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection - plug

Connector: 1 x Torson, straight; Moulded body: TPU (urethane); Locking: brass, nickel-plated



E10816




Connection cable

VDOAH040MSS00,2A03STGX030

Electrical connection

Cable: 0.2 m, PUR / PVC

Connection

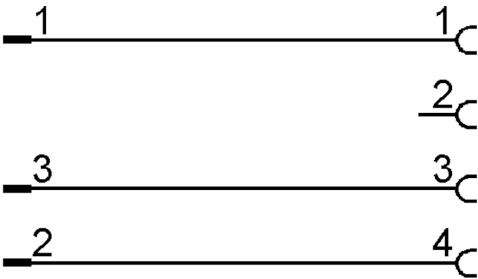

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

