


# E10819



## Patchcords with valve plug

VVSAB041--S00,3A03STAH030VAS

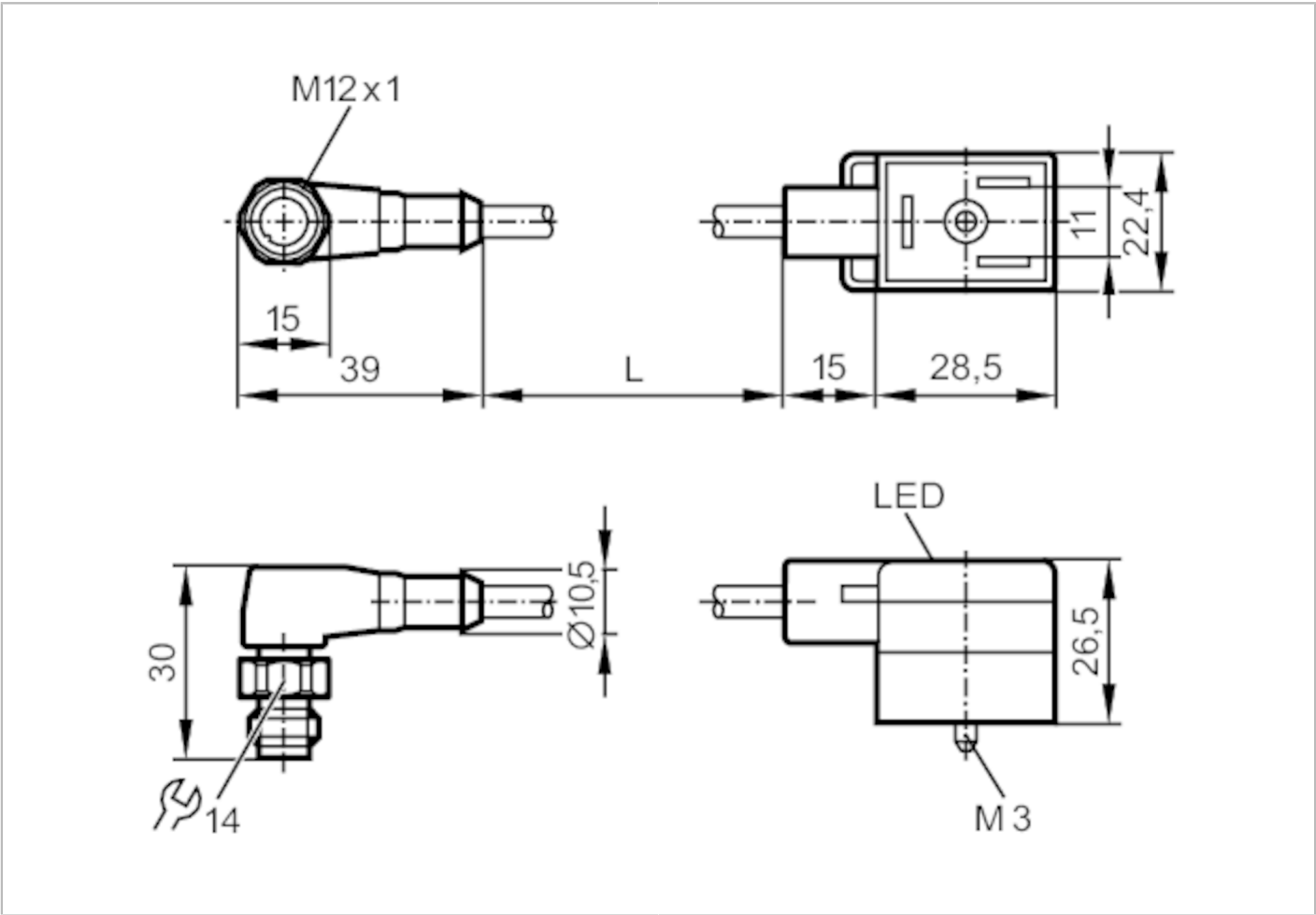

| Application                   |       |                                 |
|-------------------------------|-------|---------------------------------|
| System                        |       | Halogen-free                    |
| Electrical data               |       |                                 |
| Operating voltage             | [V]   | < 24 AC/DC                      |
| Overvoltage protection        |       | yes; (VDR)                      |
| Operating conditions          |       |                                 |
| Ambient temperature           | [°C]  | -25...90                        |
| Protection                    |       | IP 67                           |
| Mechanical data               |       |                                 |
| Weight                        | [g]   | 59.2                            |
| Dimensions                    | [mm]  | 30 x 15 x 39                    |
| Material                      |       | TPU (urethane)                  |
| Molded-body material          |       | TPU (urethane)                  |
| Material nut                  |       | stainless steel (1.4404 / 316L) |
| Displays / operating elements |       |                                 |
| Display                       | Power | 1 x LED, yellow                 |

E10819




Patchcords with valve plug

VVSAB041--S00,3A03STAH030VAS

| Accessories    |                              |
|----------------|------------------------------|
| Items supplied | screw<br>panel for labelling |
| Remarks        |                              |
| Pack quantity  | 1 pcs.                       |

Electrical connection - plug


Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: stainless steel (1.4404 / 316L)

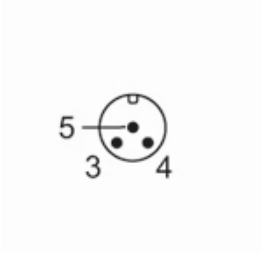

Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 4.8 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm )

Connection

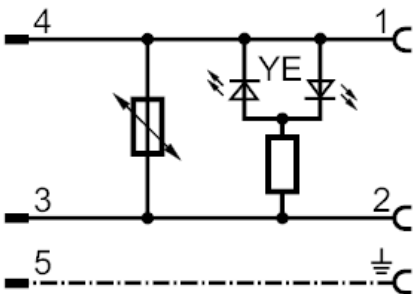

Electrical connection - Socket

Connector: 1 x valve type B industrial standard, angled; Moulded body: TPU (urethane); Locking: stainless steel (1.4404 / 316L)

