


# E10821



## Patchcords with valve plug

VVDAA040--N00,3E02STAH050VAN

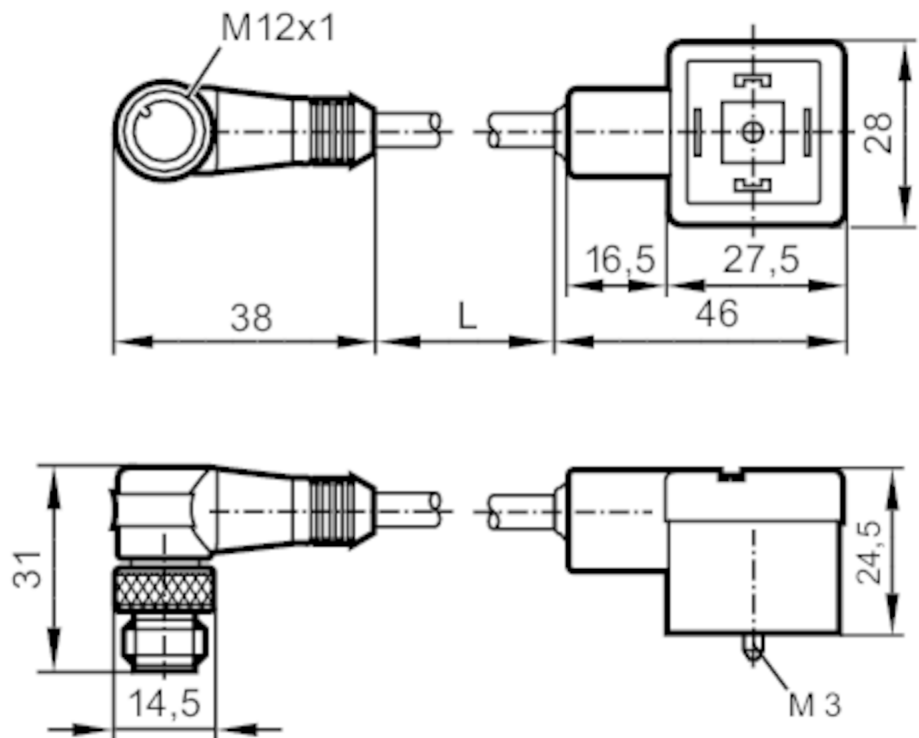

### Application

Application NAMUR

### Electrical data

Operating voltage [V] < 15 DC

### Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

### Mechanical data

Weight [g] 51.9

Dimensions [mm] 31 x 14.5 x 38

Material TPU (urethane); PUR

Molded-body material TPU / PUR

Material nut stainless steel (1.4404 / 316L)

### Accessories

Items supplied screw  
panel for labelling

### Remarks

Remarks For use in zone 0, group IIB or IIC the user has to avoid intensive electrostatic charge build-up at the sockets.

Pack quantity 1 pcs.

# E10821



## Patchcords with valve plug

VVDAA040--N00,3E02STAH050VAN

### Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: TPU / PUR; Locking: stainless steel (1.4404 / 316L)



### Electrical connection

Cable: 0.3 m, PVC, blue, Ø 5.1 mm; 2 x 0.5 mm<sup>2</sup>

### Connection



### Electrical connection - Socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU / PUR; Locking: stainless steel (1.4404 / 316L)

