


Patchcords with valve plug

VSTAH050VAN00,6E02VSAB030--N

Article no longer available - archive entry

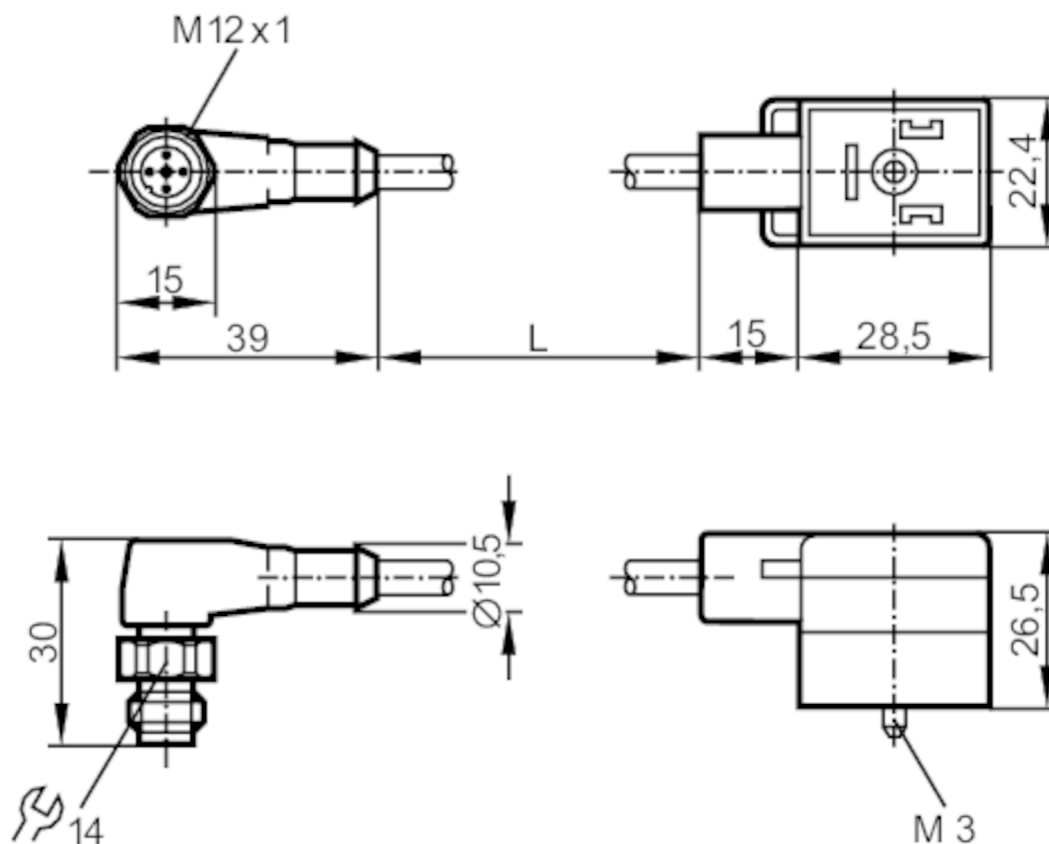

Application

Application	NAMUR
-------------	-------

Electrical data

Operating voltage	[V]	< 15 DC
-------------------	-----	---------

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Dimensions	[mm]	30 x 15 x 39
------------	------	--------------

Material	TPU (urethane); PUR
----------	---------------------

Molded-body material	TPU / PUR
----------------------	-----------

Material nut	stainless steel (1.4404 / 316L)
--------------	---------------------------------

Accessories

Items supplied	screw
	panel for labelling

Remarks

Pack quantity	1 pcs.
---------------	--------

E10824




Patchcords with valve plug

VSTAH050VAN00,6E02VSAB030--N

Electrical connection - plug


Connector: 1 x M12, angled; coding: A; Moulded body: TPU / PUR; Locking: stainless steel (1.4404 / 316L)

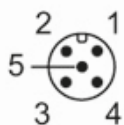

Electrical connection

Cable: 0.6 m, PVC, blue, Ø 5 mm; 2 x 0.5 mm²

 Connection



Electrical connection - Socket

Connector: 1 x valve type B DIN, angled; Moulded body: TPU / PUR; Locking: stainless steel (1.4404 / 316L)

