


E10826



Patchcords with valve plug

VVSAB030--N00,6E02STAH050VAN

Article no longer available - archive entry

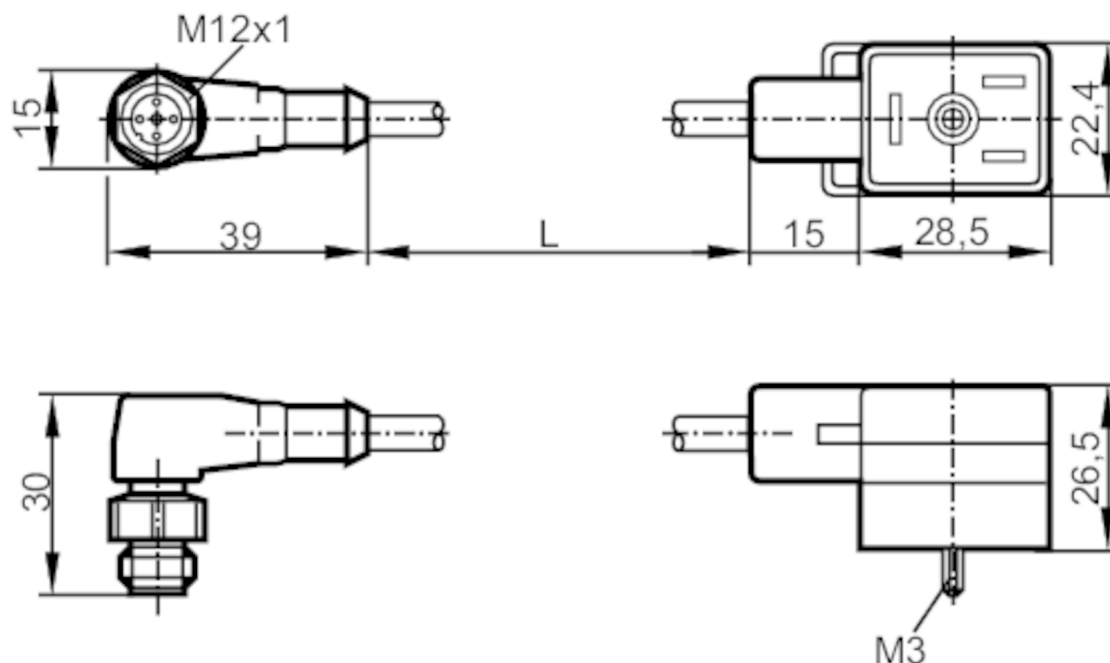

Application

Application NAMUR

Electrical data

Operating voltage [V] < 15 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 15 x 30 x 39

Material TPU (urethane); PUR

Molded-body material TPU / PUR

Material nut stainless steel (1.4404 / 316L)

Accessories

Items supplied screw
panel for labelling

Remarks

Pack quantity 1 pcs.

E10826




Patchcords with valve plug

VVSAB030--N00,6E02STAH050VAN

Electrical connection - plug


Connector: 1 x M12, angled; coding: A; Moulded body: TPU / PUR; Locking: stainless steel (1.4404 / 316L)

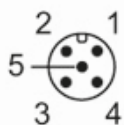

Electrical connection

Cable: 0.6 m, PVC, blue, Ø 5 mm; 2 x 0.5 mm²

 Connection



Electrical connection - Socket

Connector: 1 x valve type B industrial standard, angled; Moulded body: TPU / PUR; Locking: stainless steel (1.4404 / 316L)

