

E10827




Female cordset

ADOGH042MSS0005A04

Article no longer available - archive entry

Alternative articles: EVC645

When selecting an alternative article and accessories please note that technical data may differ!

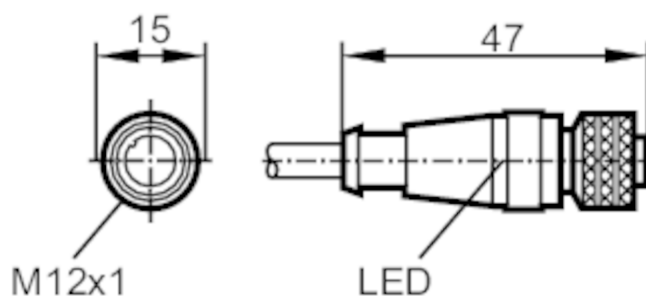

Application

System Halogen-free

Electrical data

Operating voltage [V] 10...30 DC

Operating conditions

Ambient temperature [°C] -25...80

Protection IP 67

Mechanical data

Weight [g] 163

Dimensions [mm] 15 x 15 x 47

Material PUR transparent

Molded-body material PUR, transparent

Displays / operating elements

Display	Switching status	1 x LED, yellow
	Power	1 x LED, green

Remarks

Pack quantity 1 pcs.

E10827



Female cordset

ADOGH042MSS0005A04

Electrical connection


Cable: 5 m, PUR, Halogen-free, black, Ø 4.8 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR, transparent; Tightening torque: 0.5 Nm



Connection

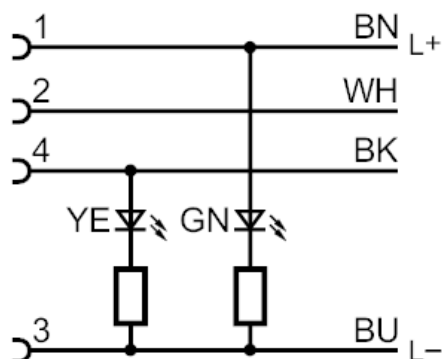

BN =	Core colors :
BK =	brown
BU =	black
WH =	blue
	white