

# E10828




## Female cordset

ADOGH040MSS0002F04

Article no longer available - archive entry

Alternative articles: E10915  
When selecting an alternative article and accessories please note that technical data may differ!

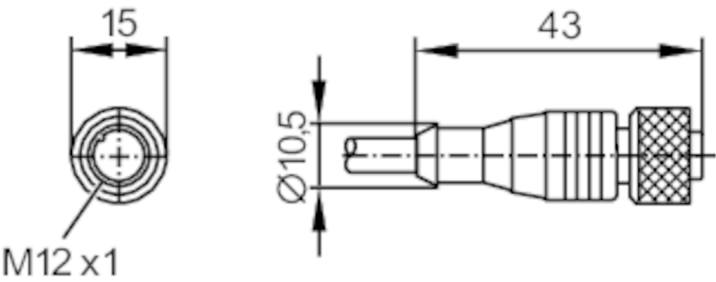

| Electrical data      |      |                      |
|----------------------|------|----------------------|
| Operating voltage    | [V]  | < 250 AC / < 300 DC  |
| Operating conditions |      |                      |
| Ambient temperature  | [°C] | -25...90             |
| Protection           |      | IP 67                |
| Mechanical data      |      |                      |
| Dimensions           | [mm] | 15 x 15 x 43         |
| Material             |      | TPU (urethane)       |
| Molded-body material |      | TPU (urethane)       |
| Material nut         |      | brass, nickel-plated |
| Remarks              |      |                      |
| Pack quantity        |      | 1 pcs.               |

# E10828



## Female cordset

ADOGH040MSS0002F04

### Electrical connection


Cable: 2 m, PVC, orange, Ø 5 mm; cross-linked; 4 x 0.34 mm² (19 x Ø 0.15 mm )

### Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



### Connection

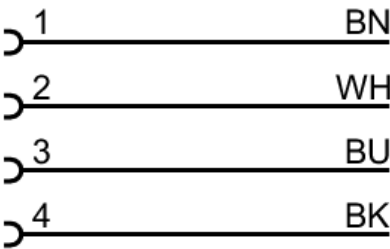

|      |               |
|------|---------------|
|      | Core colors : |
| BK = | black         |
| BN = | brown         |
| BU = | blue          |
| WH = | white         |