


E10829



Female cordset

ADOGH040MSS0005F04

Article no longer available - archive entry

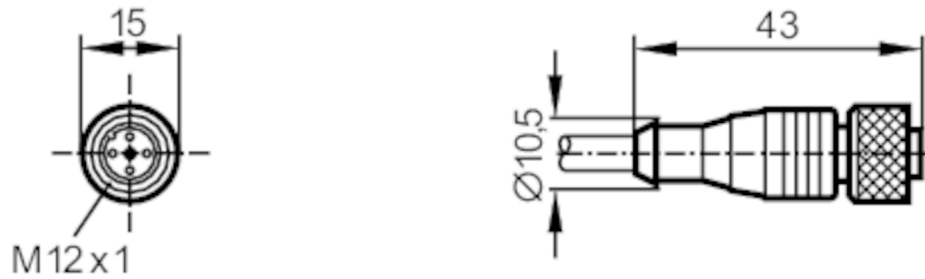

Electrical data

Operating voltage [V] < 250 AC / < 300 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 15 x 15 x 43

Material TPU (urethane)

Material nut brass, nickel-plated

Remarks

 
Pack quantity 1 pcs.

Electrical connection

Cable: 5 m, PVC, orange, Ø 5 mm; cross-linked; 4 x 0.34 mm² (19 x Ø 0.15 mm)

Electrical connection - Socket

Connector: 1 x M12, straight; Moulded body: TPU (urethane); Locking: brass, nickel-plated




E10829



Female cordset

ADOGH040MSS0005F04

Connection

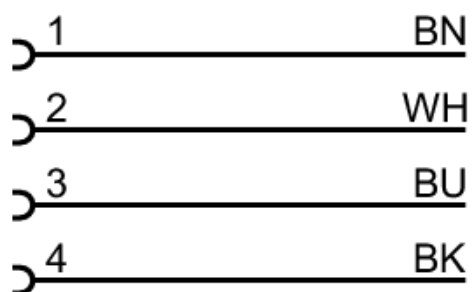

Core colors :

BK = black
BN = brown
BU = blue
WH = white

Article no longer available - archive entry