

E10830




Female cordset

ADOAF030MSS0005A03

Article no longer available - archive entry

replaced by: E11490

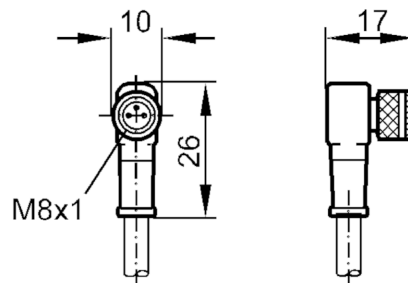

Electrical data

Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III

Operating conditions

Ambient temperature [°C]	-25...90
Protection	IP 67

Mechanical data

Dimensions [mm]	17 x 10 x 26
Material	TPU (urethane)
Material nut	brass, nickel-plated

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

 Connector: 1 x M8, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated




E10830



Female cordset

ADOAF030MSS0005A03

Connection

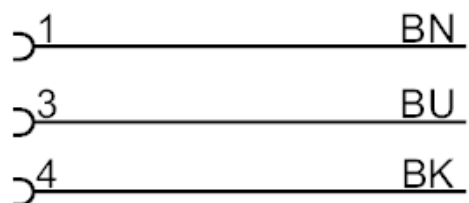

Core colors :

BN = brown
BK = black
BU = blue

Article no longer available - archive entry

replaced by: E11490