

E10835




Male receptacle

ESTGH040MSS00,5E04 (PG9)

Article no longer available - archive entry

Alternative articles: E10411
When selecting an alternative article and accessories please note that technical data may differ!

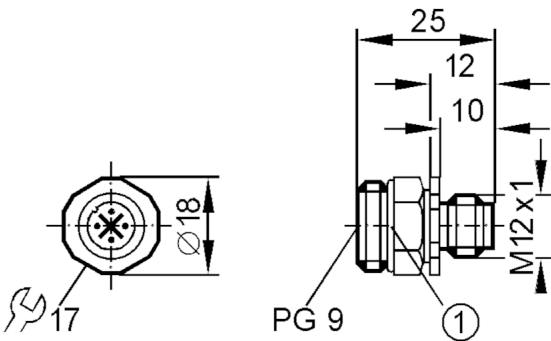

1 O-ring

Electrical data		
Operating voltage	[M]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...80
Protection		IP 67
Mechanical data		
Mounting thread		PG 9
Material		brass nickel-plated
Molded-body material		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10835



Male receptacle

ESTGH040MSS00,5E04 (PG9)

Electrical connection

Cable: 0.5 m, PVC; 4 x 0.34 mm²

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: brass, nickel-plated



Connection

1	BN
2	WH
3	BU
4	BK

BK =	Core colors :
BN =	black
BU =	brown
WH =	blue
	white