

E10837




Male cordsets

ASTAH050VAN00,6A02

Article no longer available - archive entry

Alternative articles: E10853

When selecting an alternative article and accessories please note that technical data may differ!

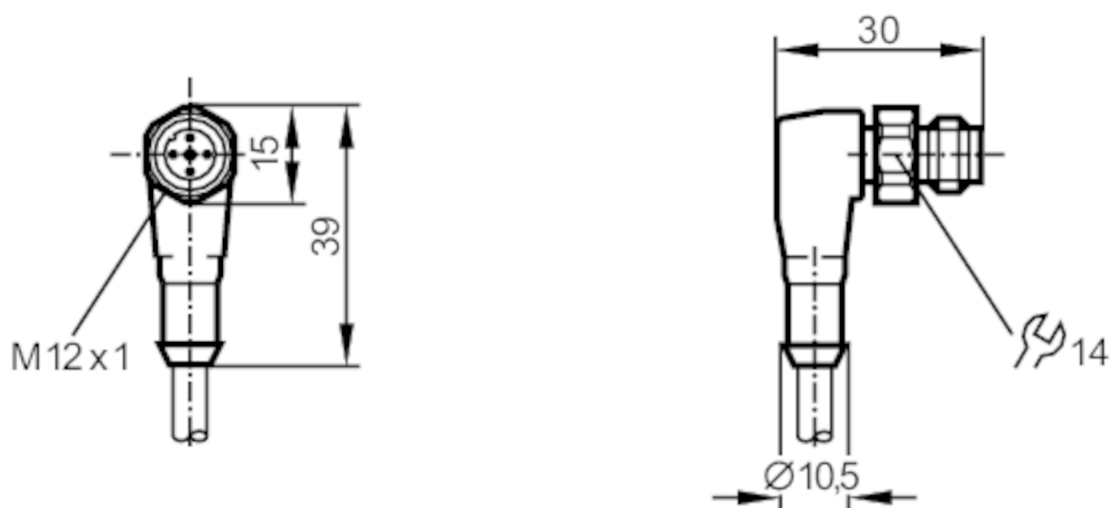

Application

Application NAMUR

Electrical data

Operating voltage [V] < 15 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 39 x 30 x 15

Material TPU (urethane)

Molded-body material TPU (urethane)

Material nut stainless steel (1.4404 / 316L)

Remarks

Pack quantity 1 pcs.

E10837



Male cordsets


ASTAH050VAN00,6A02

Electrical connection

Cable: 0.6 m, PUR / PVC, blue, Ø 5.5 mm; 2 x 0.5 mm² (16 x Ø 0.2 mm)

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: stainless steel (1.4404 / 316L)

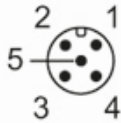

Connection

1 WH

2 BK