


E10838



Male cordsets

ASTAH050VAS00,6A03

Article no longer available - archive entry

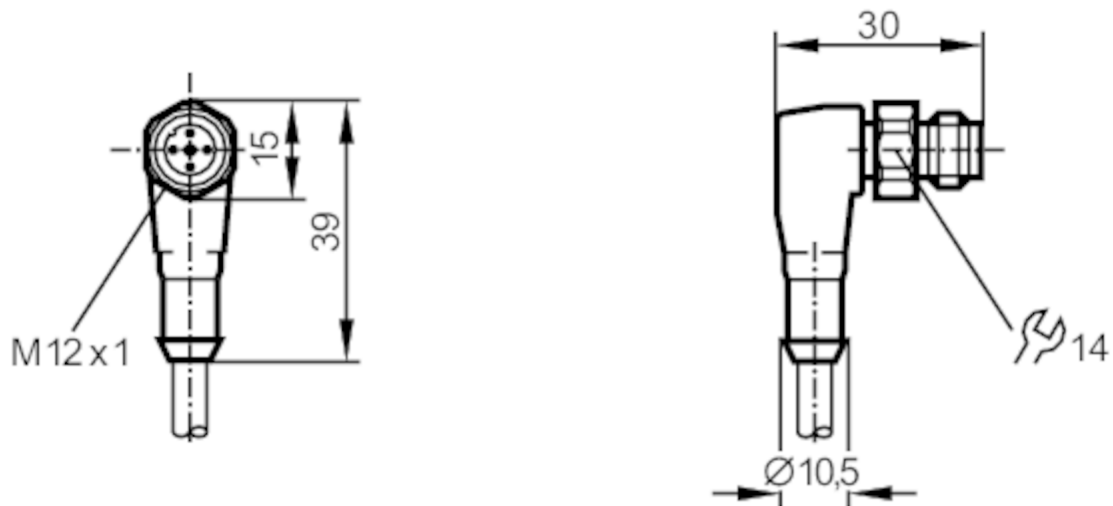

Application

System Halogen-free

Electrical data

Operating voltage [V] < 24 AC/DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 39 x 30 x 15

Material PUR; TPU (urethane)

Material nut stainless steel (1.4404 / 316L)

Remarks

 
Pack quantity 1 pcs.

Electrical connection

Cable: 0.6 m, PUR, Halogen-free, Ø 4.8 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Electrical connection - plug

Connector: 1 x M12, angled; Moulded body: PUR / TPU; Locking: stainless steel (1.4404 / 316L); Tightening torque: 0.5 Nm




E10838



Male cordsets

ASTAH050VAS00,6A03

Connection

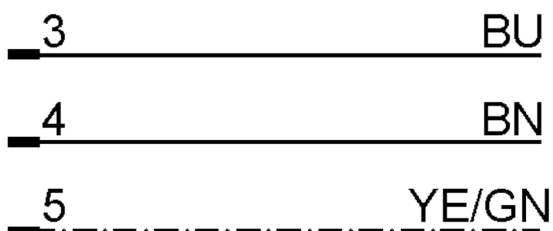

Core colors :

BN = brown
BU = blue
GN/YE = green/yellow

Article no longer available - archive entry