


E10851



Female cordset

ADOAA030VAS0005E03

Article no longer available - archive entry

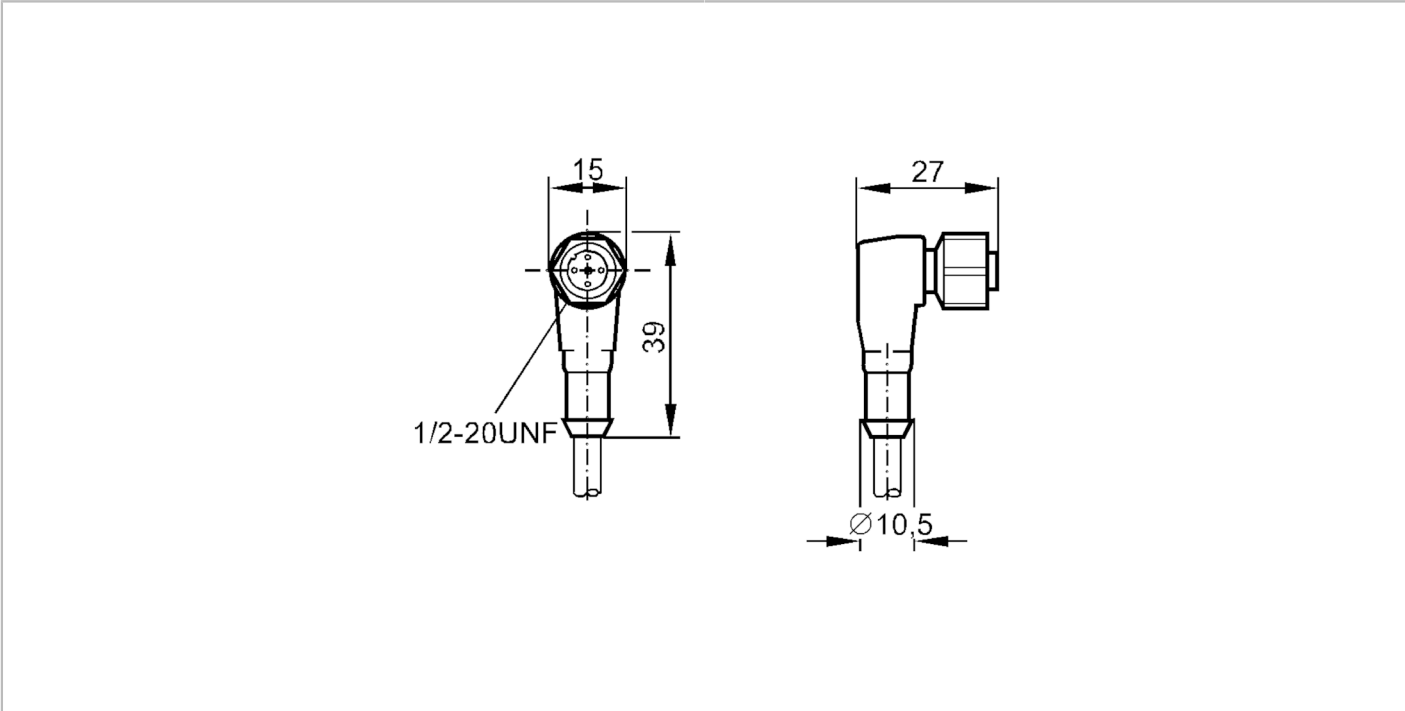

Application		
System		Free from silicone; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 250 AC
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 67
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Material		PVC
Molded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)
Remarks		
Pack quantity		1 pcs.

E10851



Female cordset

ADOAA030VAS0005E03

Electrical connection


Cable: 5 m, PVC, yellow, Ø 5 mm; 3 x 0.34 mm² (19 x Ø 0.16 mm)

Electrical connection - Socket

Connector: 1 x 1/2", angled; coding: C; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated



Connection

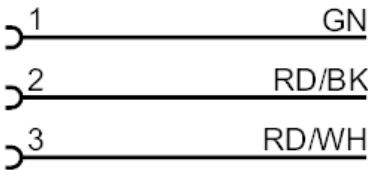

GN =
RD/BK =
RD/WH =

Core colors :
green
red/black
red/white