


E10852



Female cordset

ADOGA040VAS0005E04

Article no longer available - archive entry

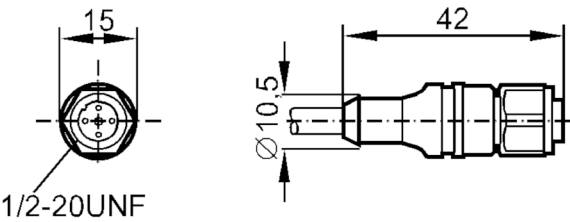

Application		
System		Free from silicone; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 250 AC
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 42
Material		PVC
Molded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)
Remarks		
Pack quantity		1 pcs.

E10852



Female cordset


ADOGA040VAS0005E04

Electrical connection

Cable: 5 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x 1/2", straight; coding: C; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated

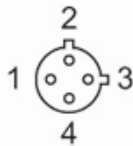

Connection



BK =	Core colors :
BN =	black
BU =	brown
WH =	blue
	white