


E10853



Male cordsets

ASTAH050VAN00,6A02

Article no longer available - archive entry

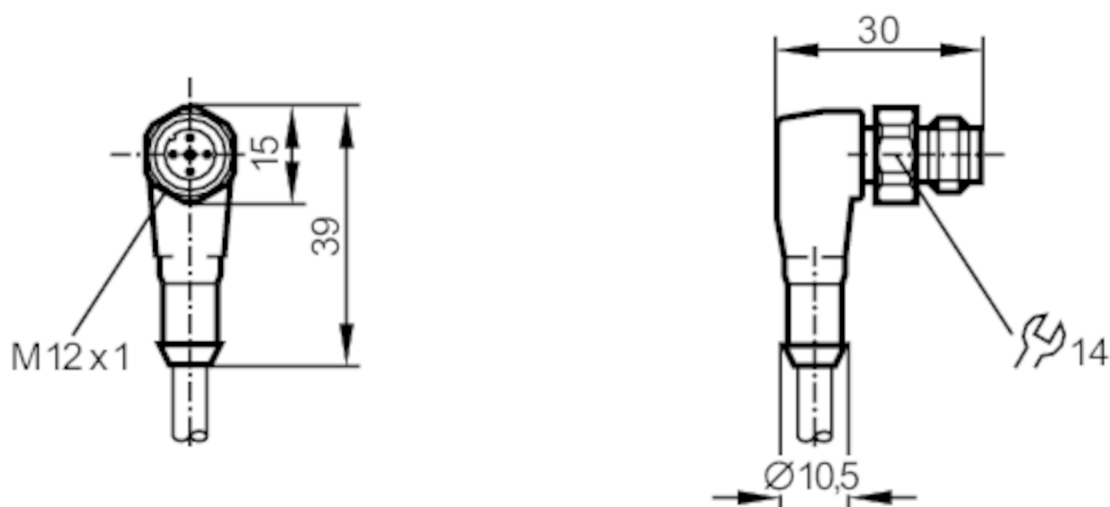

Application

Application

NAMUR

Electrical data

Operating voltage

[V]

< 15 DC

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Dimensions

[mm]

39 x 30 x 15

Material

TPU (urethane)

Molded-body material

TPU (urethane)

Material nut

stainless steel (1.4404 / 316L)

Remarks

Pack quantity

1 pcs.

E10853



Male cordsets


ASTAH050VAN00,6A02

Electrical connection

Cable: 0.6 m, PVC, blue, Ø 5.5 mm; 2 x 0.5 mm² (16 x Ø 0.2 mm)

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: stainless steel (1.4404 / 316L); Tightening torque: 0.5 Nm

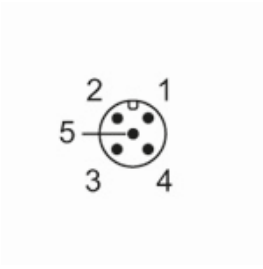

Connection

1 WH

2 BK