


E10862



Female cordset

ADOAF040MSS0005E04

Article no longer available - archive entry

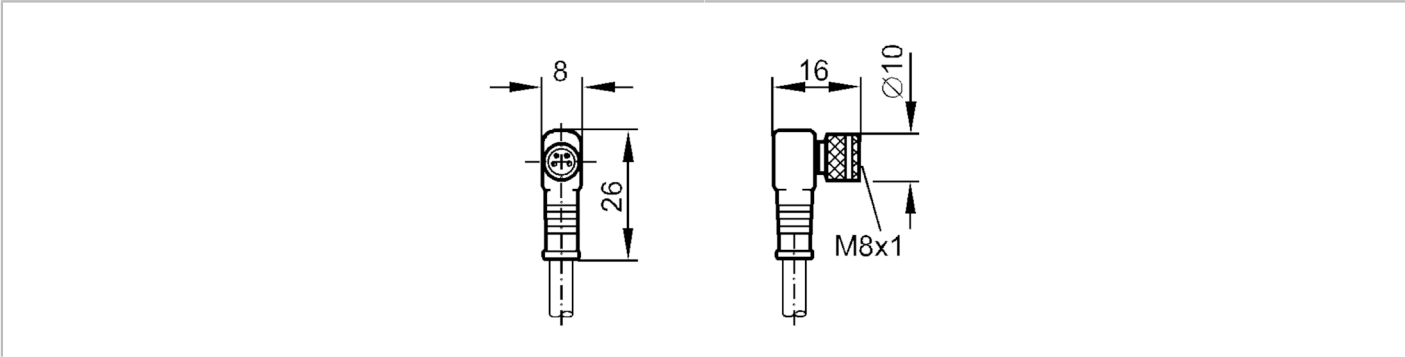

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67; (if screwed on)

Mechanical data

Dimensions	[mm]	16 x 8 x 26
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

Cable: 5 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm²

Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated




E10862



Female cordset

ADOAF040MSS0005E04

Connection

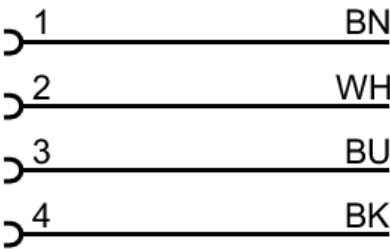

	Core colors :
BK =	black
BN =	brown
BU =	blue
WH =	white