


E10868



Female cordset


ADOGH030MSS0005E03

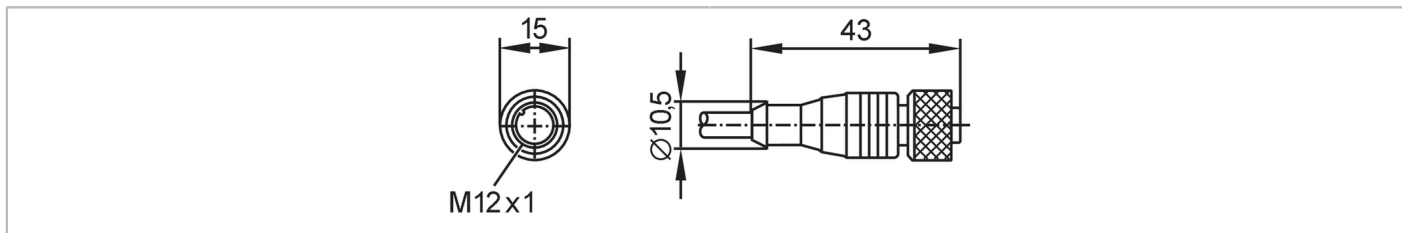


Application	
Application	Industrial applications
Electrical data	
Operating voltage [V]	< 250 AC / < 300 DC
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 67
Mechanical data	
Weight [g]	198.3
Dimensions [mm]	15 x 15 x 43
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 5 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm ² (19 x Ø 0.16 mm) / AWG 22	

Electrical connection - Socket

 Connector: 1 x M12, straight; coding: C; Contacts: 3; Moulded body: TPU (urethane), orange; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Connection

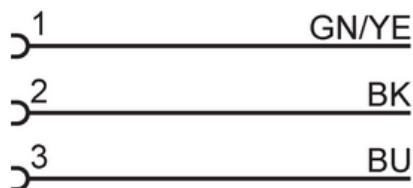

Core colors :
 BK = black
 BU = blue
 GN/YE = green/yellow