


E10871



Female cordset

ADOAH043MSS0010H04

Article no longer available - archive entry

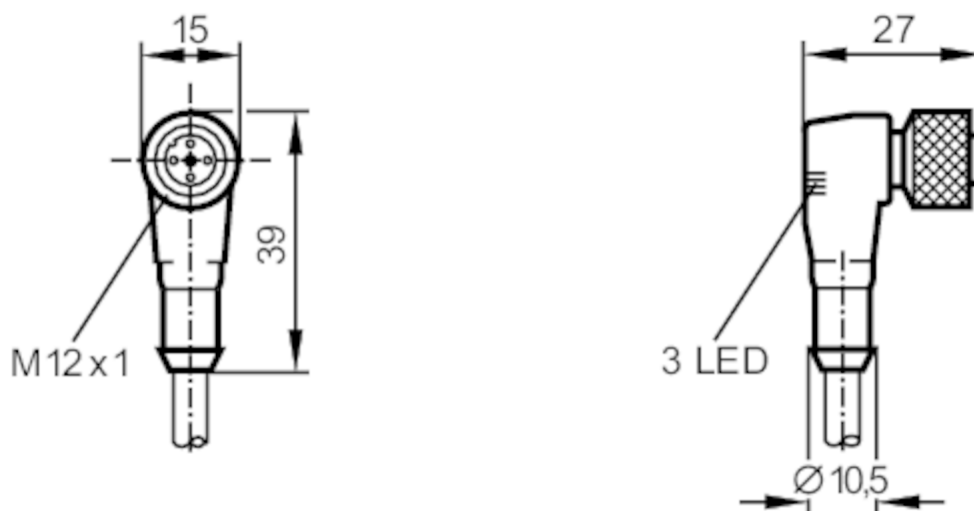

Application

System

Halogen-free

Electrical data

Operating voltage

[V]

10...30 DC

Outputs

Electrical design

PNP

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Dimensions

[mm]

27 x 15 x 39

Material

TPU (urethane)

Molded-body material

TPU (urethane)

Material nut

brass, weld coated

Displays / operating elements

Display

Switching status

2 x LED, yellow

Power

1 x LED, green

Remarks

Pack quantity

1 pcs.

E10871



Female cordset

ADOAH043MSS0010H04

Electrical connection


Cable: 10 m, PUR, Halogen-free; cross-linked; 4 x 0.34 mm² (19 x Ø 0.15 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, weld coated



Connection

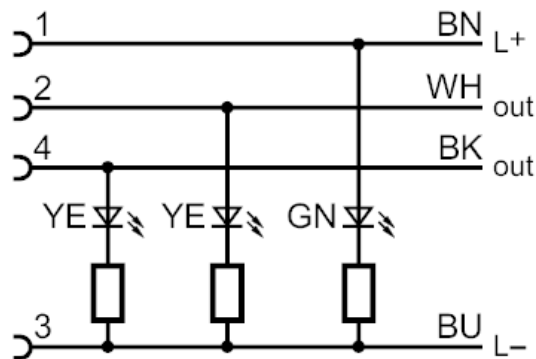

BK =	Core colors :
BN =	black
BU =	brown
WH =	blue
	white