

E10883




Connection cable

VDOGH040MSS0002I04STGH040MSS

Article no longer available - archive entry

Alternative articles: E10884
When selecting an alternative article and accessories please note that technical data may differ!

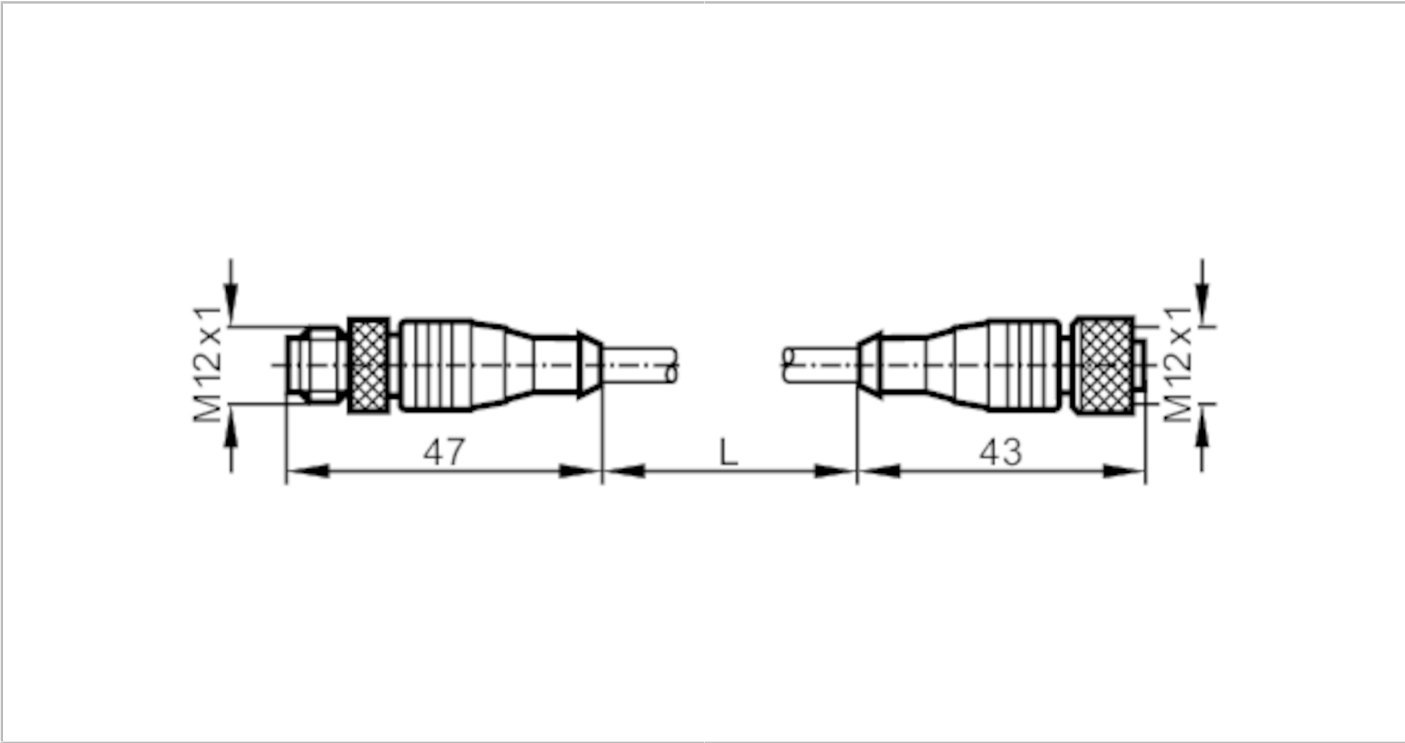

Application	
System	Halogen-free; gold-plated contacts
Electrical data	
Operating voltage [V]	< 250 AC / < 300 DC
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 67
Mechanical data	
Material	TPU (urethane)
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

E10883



Connection cable

VDOGH040MSS0002I04STGH040MSS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.5 Nm



Electrical connection

Cable: 2 m, PUR, Halogen-free, black, Ø 4.8 mm; cross-linked; 4 x 0.34 mm² (19 x Ø 0.15 mm)

Connection

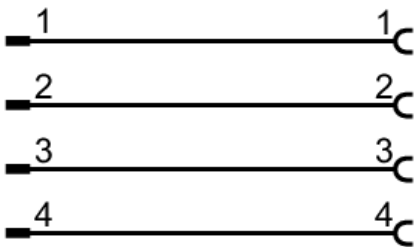

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.5 Nm

