




Female wirable connectors


SDOGK190MSSFKPG

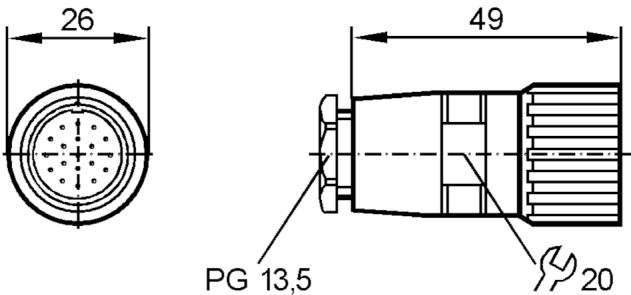

Electrical data		
Operating voltage	[V]	10...30 DC
Max. current load total	[A]	7.5
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 65
Mechanical data		
Weight	[g]	82.4
Dimensions	[mm]	26 x 26 x 49
Material		brass nickel-plated
Molded-body material		brass, nickel-plated
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection	
soldering: ...1 mm²; Cable sheath: Ø 10...14 mm	

Electrical connection - Socket	
Connector: 1 x M23, straight; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated	

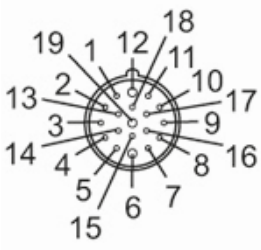

E10887



Female wirable connectors

SDOGK190MSSFKPG

Connection

