


E10895



Female cordset

ADOGK120MSS0005A

Article no longer available - archive entry

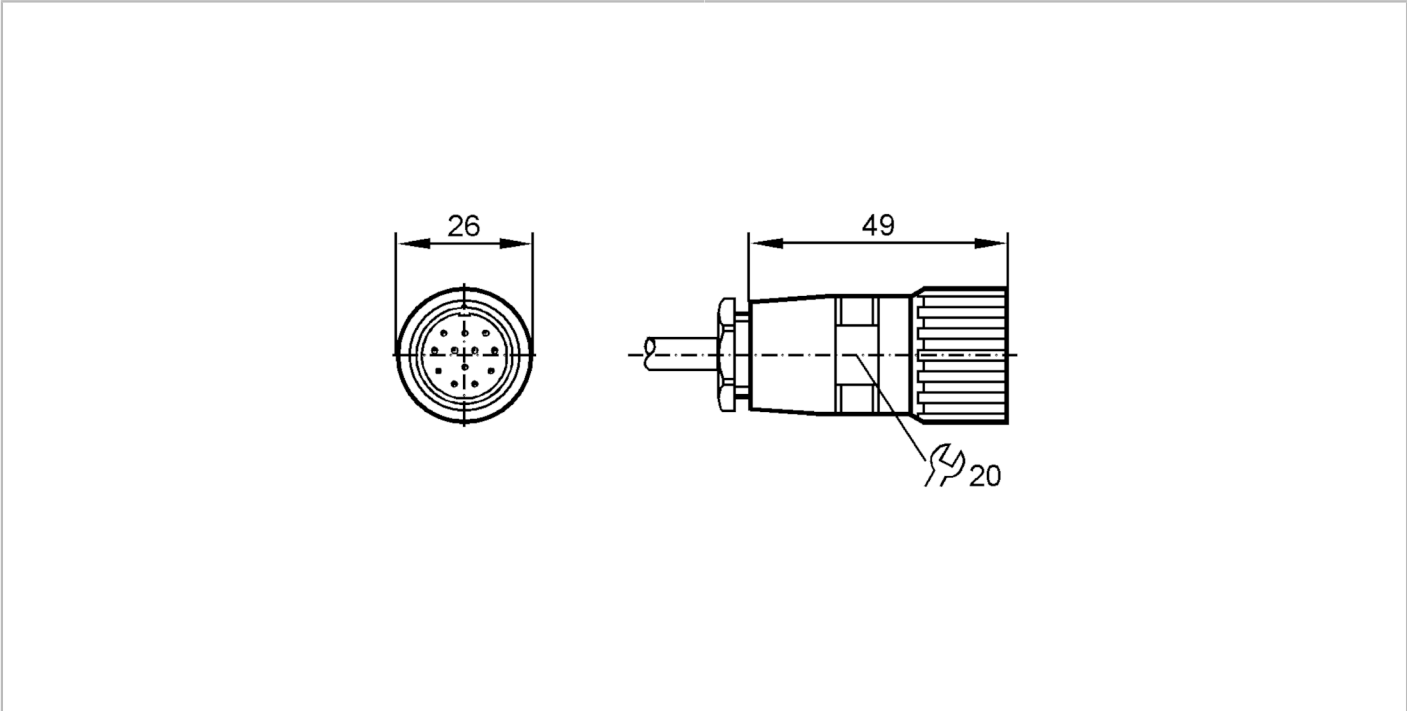

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 65

Mechanical data

Dimensions	[mm]	26 x 26 x 49
Material		brass nickel-plated
Molded-body material		brass, nickel-plated
Material nut		brass, nickel-plated

Remarks


Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

Cable: 5 m, PUR; 12 x 1.0 mm² (128 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M23, straight; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated

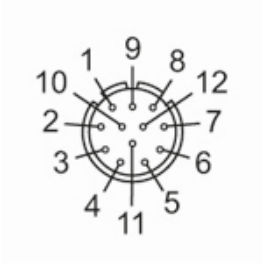

E10895



Female cordset

ADOGK120MSS0005A

Connection

1	BK 1
2	BK 2
3	BK 3
4	BK 4
5	BK 5
6	BK 6
7	BK 7
8	BK 8
9	BK 9
10	BK 10
11	BK 11
12	GN/YE