

# E10910




## Female cordset

ADOAH040SCS0005I04

Article no longer available - archive entry

Alternative articles: EVW005

When selecting an alternative article and accessories please note that technical data may differ!

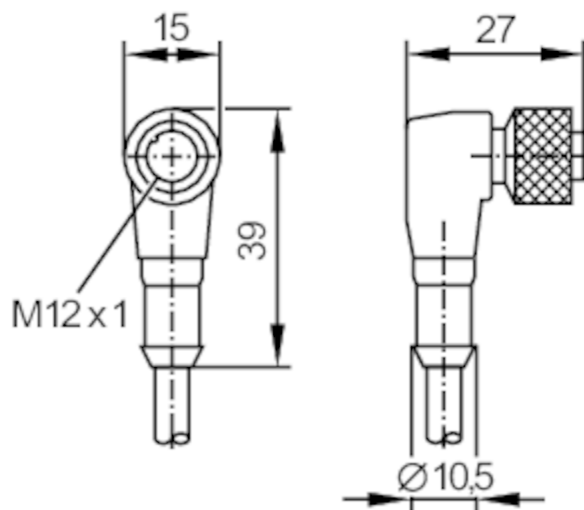

### Application

|                    |                                                        |
|--------------------|--------------------------------------------------------|
| System             | Free from silicone; Halogen-free; gold-plated contacts |
| Free from silicone | yes                                                    |

### Electrical data

|                         |     |                     |
|-------------------------|-----|---------------------|
| Operating voltage       | [V] | < 250 AC / < 300 DC |
| Max. current load total | [A] | 4                   |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection          |      | IP 68    |

### Mechanical data

|                      |      |                    |
|----------------------|------|--------------------|
| Dimensions           | [mm] | 27 x 15 x 39       |
| Material             |      | TPU (urethane)     |
| Molded-body material |      | TPU (urethane)     |
| Material nut         |      | brass, weld coated |

### Remarks

|               |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |
|---------------|--|--------|

# E10910



## Female cordset


ADOAH040SCS0005I04

### Electrical connection


Cable: 5 m, PUR, Halogen-free, black, Ø 4.8 mm; cross-linked; 4 x 0.34 mm<sup>2</sup>

### Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, weld coated; Contacts: gold-plated; Tightening torque: 0.5 Nm

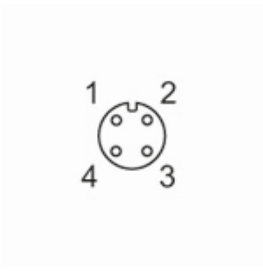

### Connection

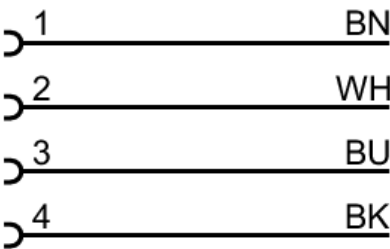

Core colors :  
BK = black  
BN = brown  
BU = blue  
WH = white