

E10914




Female cordset

ADOAH043SCS0010I04

Article no longer available - archive entry

Alternative articles: EVW009

When selecting an alternative article and accessories please note that technical data may differ!

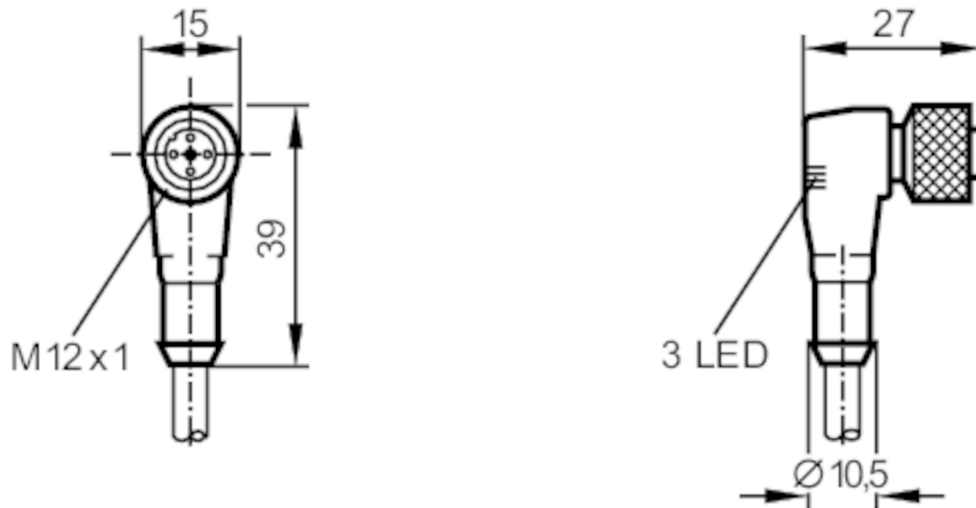

Application

System	Free from silicone; Halogen-free; gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...30 DC
Max. current load total	[A]	4

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Dimensions	[mm]	27 x 15 x 39
Material		TPU (urethane) transparent
Molded-body material		TPU (urethane), transparent
Material nut		brass, weld coated

Displays / operating elements

Display	Switching status	2 x LED, yellow
	Power	1 x LED, green

E10914



Female cordset

ADOAH043SCS0010I04

Remarks


Pack quantity 1 pcs.

Electrical connection


Cable: 10 m, PUR, Halogen-free, black, Ø 4.8 mm; cross-linked; 4 x 0.34 mm²

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane), transparent; Locking: brass, weld coated; Contacts: gold-plated; Tightening torque: 0.5 Nm

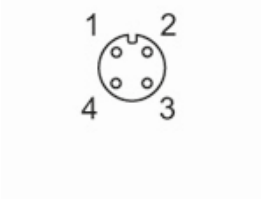

Connection

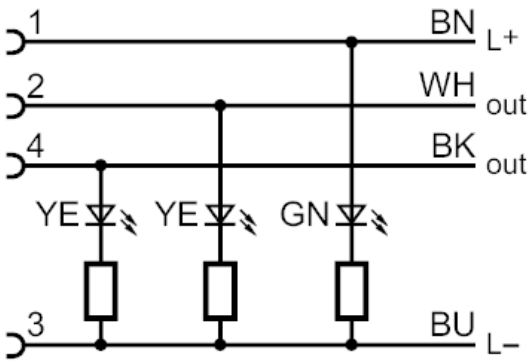

BK = Core colors :
BN = black
BU = brown
WH = blue
white