

E10923




Connection cable

VDOAF030MSS00,3H03STGF030MSS

Article no longer available - archive entry

Alternative articles: E11324
When selecting an alternative article and accessories please note that technical data may differ!

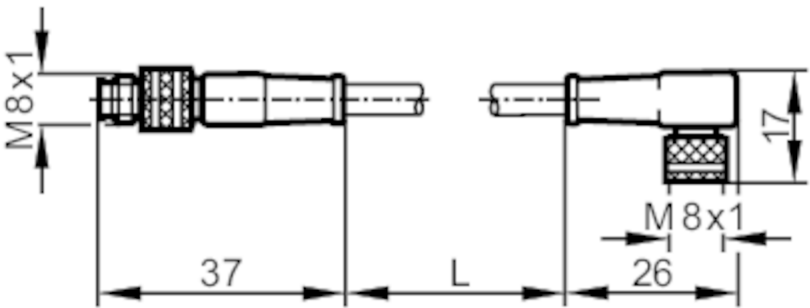

Application	
System	Halogen-free
Electrical data	
Operating voltage [V]	10...30 DC
Protection class	III
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 67
Mechanical data	
Material	TPU (urethane)
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

E10923

 


Connection cable

VDOAF030MSS00,3H03STGF030MSS

Electrical connection - plug


Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Electrical connection

Cable: 0.3 m, TPU (urethane), Halogen-free; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Connection

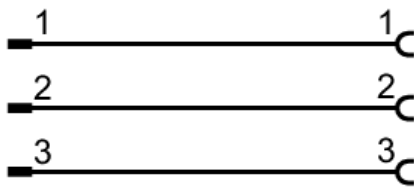

Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

