


E10924



Connection cable

VDOGG030--S00,6H03STGF030MSS

Article no longer available - archive entry

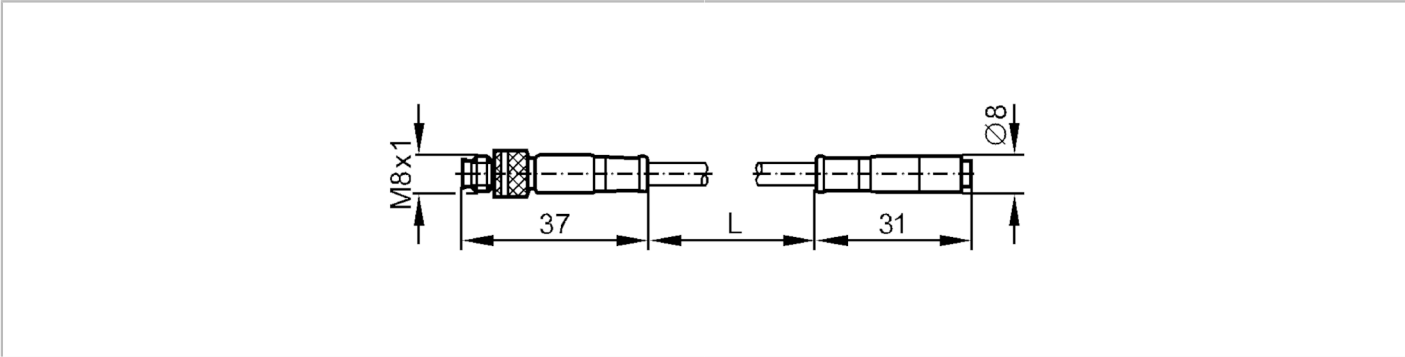

Application

|        |              |
|--------|--------------|
| System | Halogen-free |
|--------|--------------|

Electrical data

|                   |     |            |
|-------------------|-----|------------|
| Operating voltage | [V] | 10...55 DC |
| Protection class  |     | III        |

Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection          |      | IP 65    |

Mechanical data


|                      |                      |
|----------------------|----------------------|
| Material             | TPU (urethane)       |
| Molded-body material | TPU (urethane)       |
| Material nut         | brass, nickel-plated |

Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

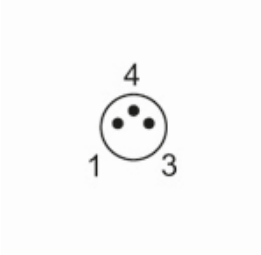

# E10924



## Connection cable

VDOGG030--S00,6H03STGF030MSS

### Electrical connection

Cable: 0.6 m, TPU (urethane), Halogen-free; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

#### Connection



### Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

