


E10925



Connection cable

VDOGG030--S0001H03STGF030MSS

Article no longer available - archive entry

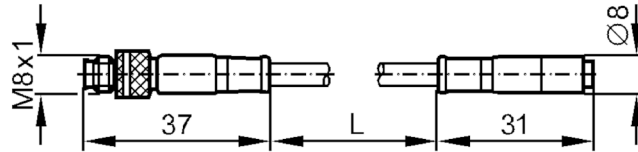

Application

System Halogen-free

Electrical data

Operating voltage [V] 10...55 DC

Protection class III

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 65

Mechanical data

Material TPU (urethane)

 
Material nut brass, nickel-plated / brass, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection - plug

Connector: 1 x M8, straight; Moulded body: TPU (urethane); Locking: brass, nickel-plated



E10925




Connection cable

VDOGG030--S0001H03STGF030MSS

Electrical connection


Cable: 1 m, Halogen-free; 3 x 0.34 mm²

Connection

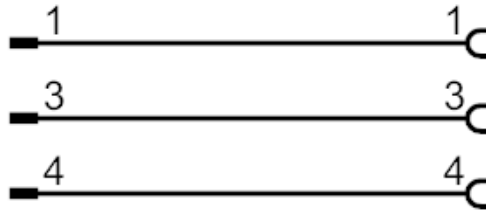

Electrical connection - Socket

 Connector: 1 x M8, straight; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Article no longer available - archive entry