


E10932



Connection cable

VDOAF032MSS0001H03STGF030MSS

Article no longer available - archive entry

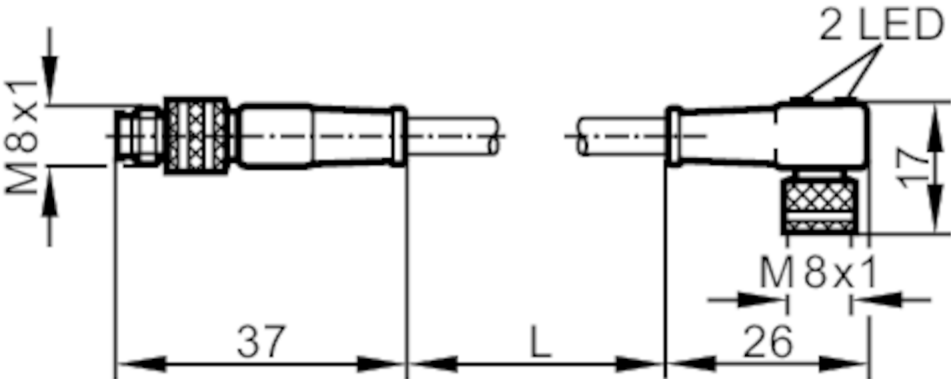

Application		
System	Halogen-free	
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class	III	
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection	IP 67	
Mechanical data		
Material	TPU (urethane)	
Molded-body material	TPU (urethane)	
Material nut	brass, nickel-plated	
Displays / operating elements		
Display	Switching status	1 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity	1 pcs.	

E10932



Connection cable

VDOAF032MSS0001H03STGF030MSS

Electrical connection - plug


Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Electrical connection

Cable: 1 m, Halogen-free; 3 x 0.34 mm²

Connection

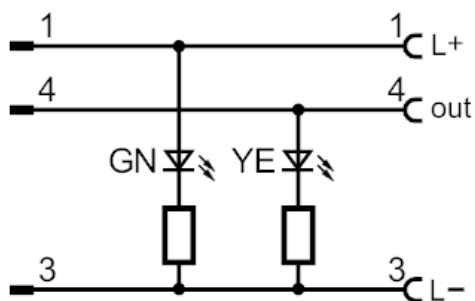

Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

