


E10935



Connection cable

VDOGH040MSS0001H03STGF030MSS

Article no longer available - archive entry

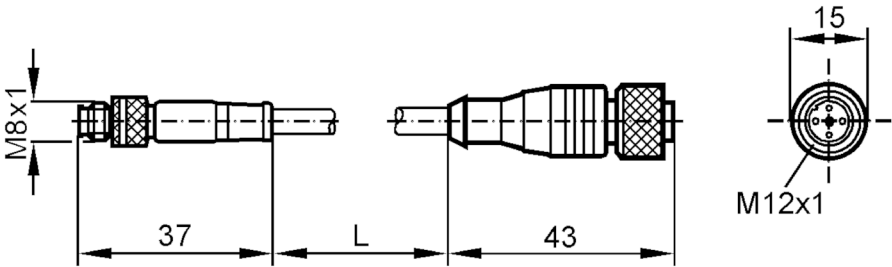

| Application                  |      |                      |
|------------------------------|------|----------------------|
| System                       |      | Halogen-free         |
| Electrical data              |      |                      |
| Operating voltage            | [V]  | 10...30 DC           |
| Protection class             |      | III                  |
| Operating conditions         |      |                      |
| Ambient temperature          | [°C] | -25...90             |
| Protection                   |      | IP 67                |
| Mechanical data              |      |                      |
| Material                     |      | TPU (urethane)       |
| Molded-body material         |      | TPU (urethane)       |
| Material nut                 |      | brass, nickel-plated |
| Remarks                      |      |                      |
| Pack quantity                |      | 1 pcs.               |
| Electrical connection - plug |      |                      |

Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



# E10935




## Connection cable

VDOGH040MSS0001H03STGF030MSS

### Electrical connection

Cable: 1 m, Halogen-free; 3 x 0.34 mm<sup>2</sup>

### Connection

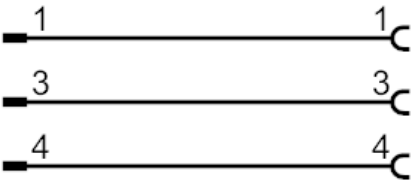

### Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

