

E10946




Wiring block

ZDO6H059MSS0000-00STAM190MSS

Article no longer available - archive entry

Alternative articles: EBC008
When selecting an alternative article and accessories please note that technical data may differ!

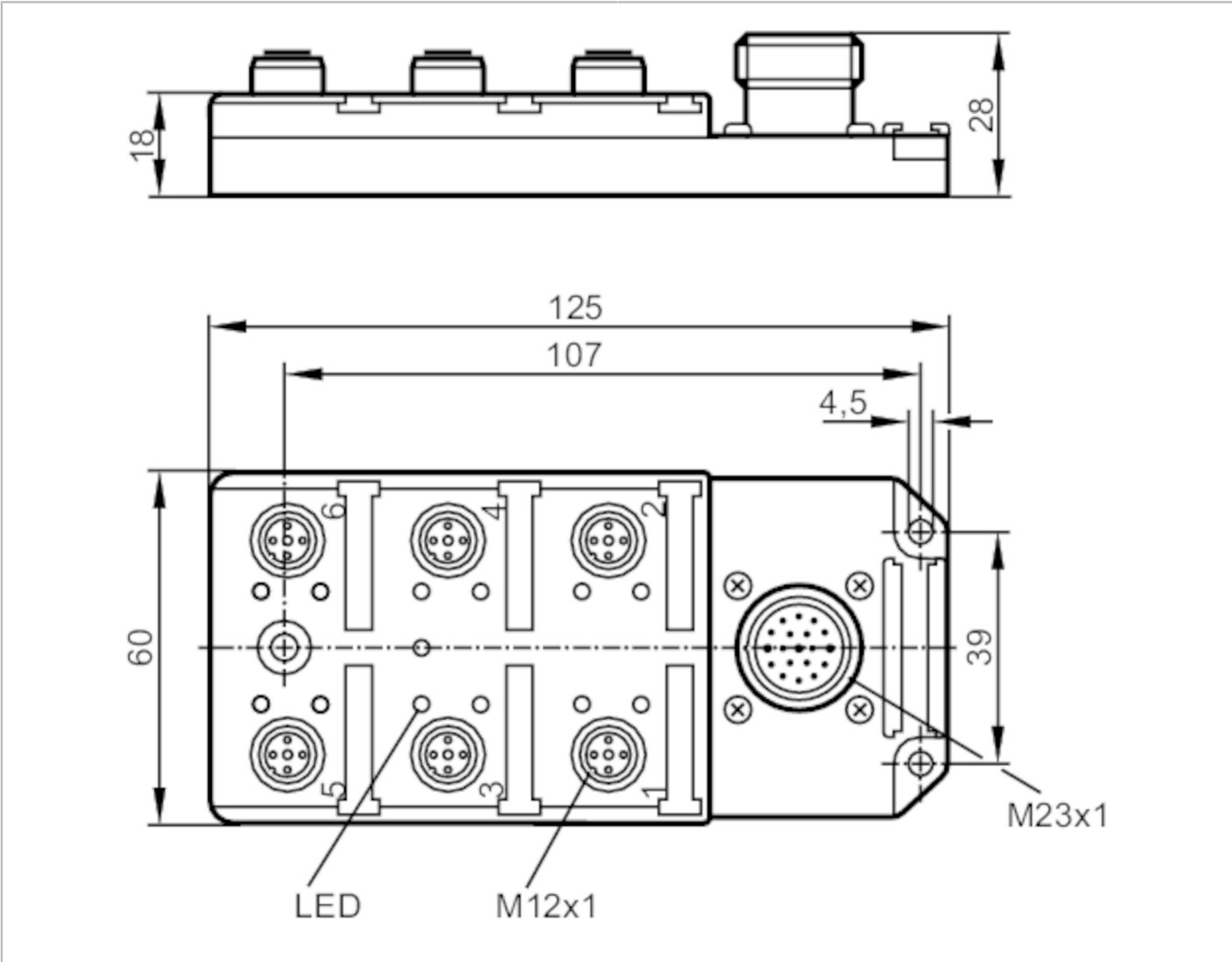

Application		
System		Free from silicone; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	10
Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67

E10946



Wiring block

ZDO6H059MSS0000-00STAM190MSS

Mechanical data		
Dimensions	[mm]	28 x 60 x 125
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Number of ports splitter box		6
Connector type		M12
Displays / operating elements		
Display	Switching status	12 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.
Electrical connection - Connection		
Connector: 1 x M23; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm		



Wiring block

ZDO6H059MSS0000-00STAM190MSS

Connection



E10946



Wiring block

ZDO6H059MSS0000-00STAM190MSS

Electrical connection - slot

Connector: 6 x M12; coding: A; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm

