

E10954




Female cordset

ADOGH050VAS0005E05

Article no longer available - archive entry

Alternative articles: EVT010

When selecting an alternative article and accessories please note that technical data may differ!

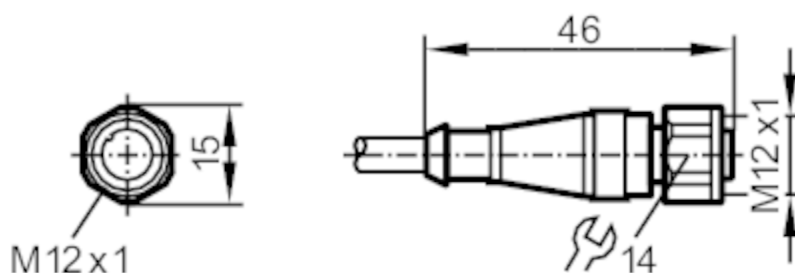

Application

System	Free from silicone; gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...100
Protection		IP 68

Mechanical data

Dimensions	[mm]	15 x 15 x 46
Material		PVC
Molded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)

Remarks

Pack quantity	1 pcs.
---------------	--------

E10954



Female cordset


ADOGH050VAS0005E05

Electrical connection


Cable: 5 m, PVC, orange, Ø 5.6 mm; 5 x 0.25 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

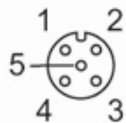

Connection

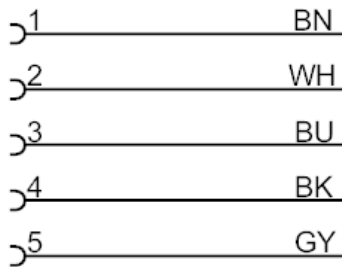

Core colors :
BK = black
BN = brown
BU = blue
GY = grey
WH = white