


E10958



Female cordset

ADOAH050SCS0005I05

Article no longer available - archive entry

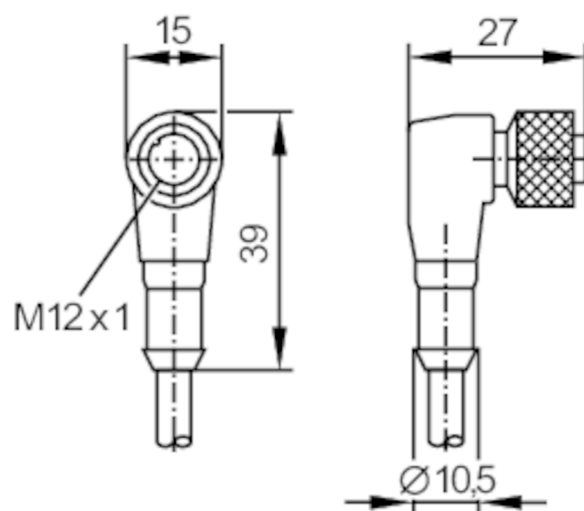

Application

System	Free from silicone; Halogen-free; gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Dimensions	[mm]	27 x 15 x 39
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, weld coated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E10958



Female cordset


ADOAH050SCS0005I05

Electrical connection


Cable: 5 m, PUR, Halogen-free, black, Ø 5.5 mm; cross-linked; 5 x 0.34 mm²

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, weld coated; Contacts: gold-plated; Tightening torque: 0.5 Nm

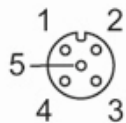

Connection

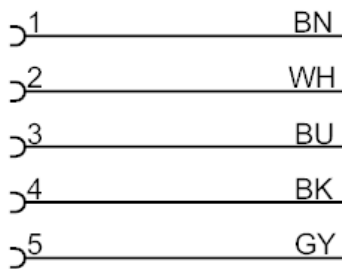

Core colors :

BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white