

E10960




Female cordset

ADOGH050SCS0002I05

Article no longer available - archive entry

Alternative articles: EVW010

When selecting an alternative article and accessories please note that technical data may differ!

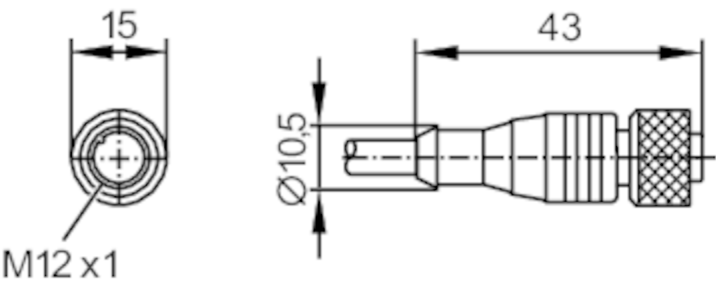

Application		
System		Free from silicone; Halogen-free; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Dimensions	[mm]	15 x 15 x 43
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, weld coated
Remarks		
Pack quantity		1 pcs.

E10960



Female cordset

ADOGH050SCS0002I05

Electrical connection


Cable: 2 m, PUR, Halogen-free, black, Ø 5.5 mm; cross-linked; 5 x 0.34 mm² (19 x Ø 0.15 mm)

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, weld coated; Contacts: gold-plated; Tightening torque: 0.5 Nm



Connection

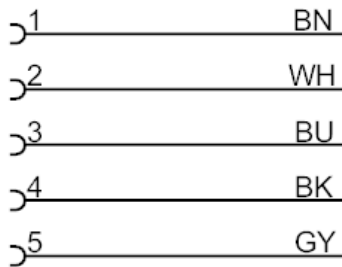

	Core colors :
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white