

E10967



Female cordset

ADOGH050MSS0005H05

Article no longer available - archive entry



Application		
System		Free from silicone; Halogen-free; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Dimensions	[mm]	15 x 15 x 43
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10967



Female cordset

ADOGH050MSS0005H05

Electrical connection


Cable: 5 m, PUR, Halogen-free, black, Ø 5.5 mm; 5 x 0.34 mm²

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.5 Nm



Connection

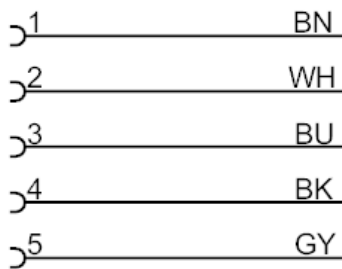

Core colors :
BK = black
BN = brown
BU = blue
GY = grey
WH = white