


# E10968



## Female cordset

ADOGH050MSS0010H05

Article no longer available - archive entry

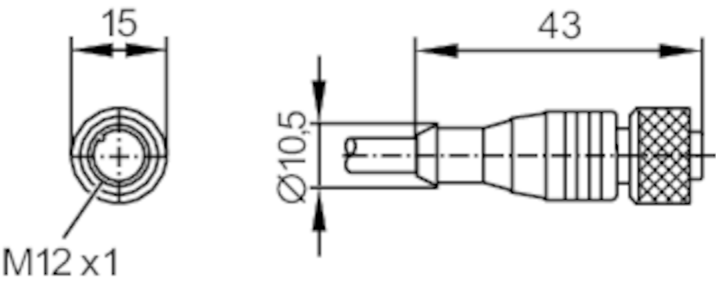

| Application             |      |                                                        |
|-------------------------|------|--------------------------------------------------------|
| System                  |      | Free from silicone; Halogen-free; gold-plated contacts |
| Free from silicone      |      | yes                                                    |
| Electrical data         |      |                                                        |
| Operating voltage       | [V]  | < 30 AC / < 36 DC                                      |
| Max. current load total | [A]  | 4                                                      |
| Operating conditions    |      |                                                        |
| Ambient temperature     | [°C] | -25...90                                               |
| Protection              |      | IP 68                                                  |
| Mechanical data         |      |                                                        |
| Dimensions              | [mm] | 15 x 15 x 43                                           |
| Material                |      | TPU (urethane)                                         |
| Molded-body material    |      | TPU (urethane)                                         |
| Material nut            |      | brass, nickel-plated                                   |
| Remarks                 |      |                                                        |
| Pack quantity           |      | 1 pcs.                                                 |

# E10968



## Female cordset


ADOGH050MSS0010H05

### Electrical connection


Cable: 10 m, PUR, Halogen-free, black, Ø 5.5 mm; 5 x 0.34 mm<sup>2</sup>

### Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.5 Nm

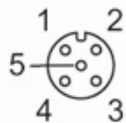

### Connection

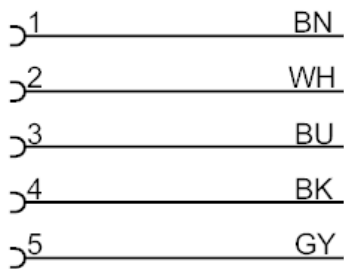

Core colors :

|      |       |
|------|-------|
| BK = | black |
| BN = | brown |
| BU = | blue  |
| GY = | grey  |
| WH = | white |