


E10969



Female cordset

ADOAF032VAS0005E03

Article no longer available - archive entry

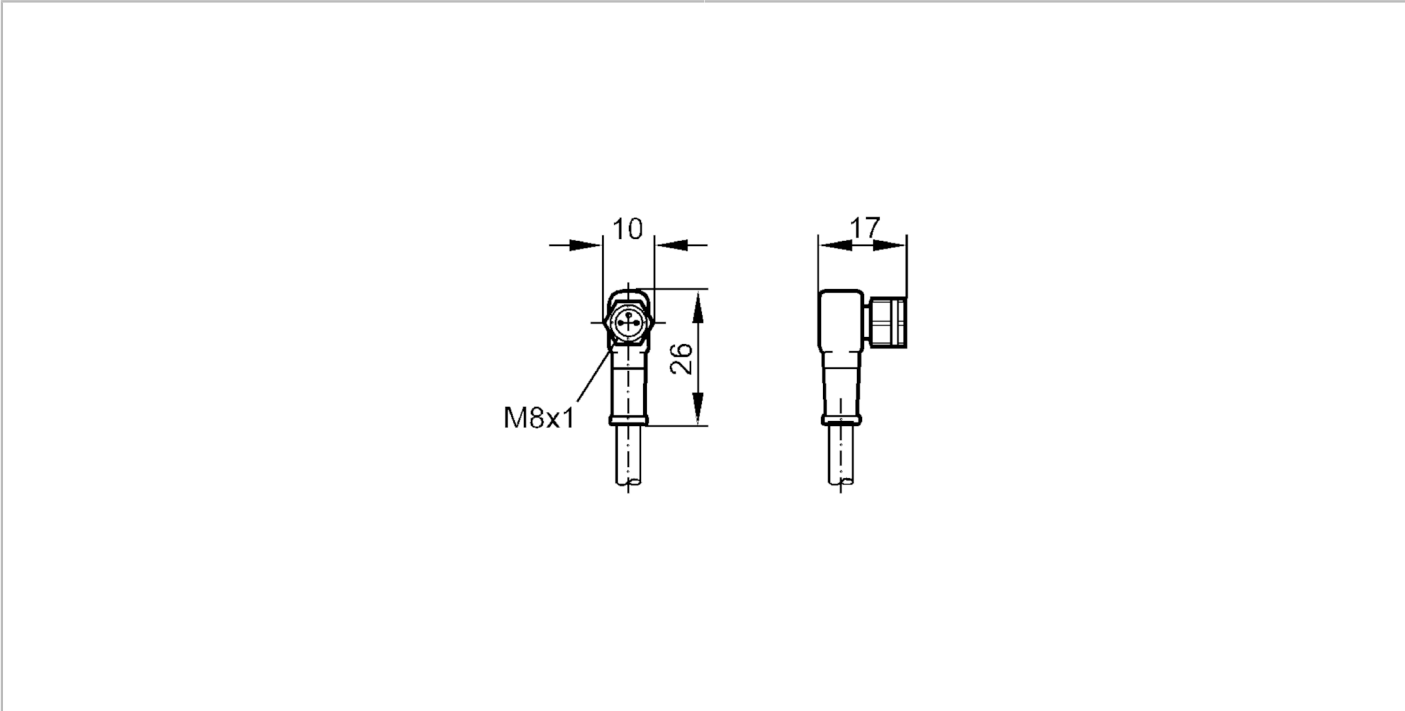

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Material		TPU (urethane) transparent
Molded-body material		TPU (urethane), transparent
Material nut		stainless steel (1.4404 / 316L)
Displays / operating elements		
Display	Switching status	1 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10969



Female cordset

ADOAF032VAS0005E03

Electrical connection


Cable: 5 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU (urethane), transparent; Locking: stainless steel (1.4404 / 316L)



Connection

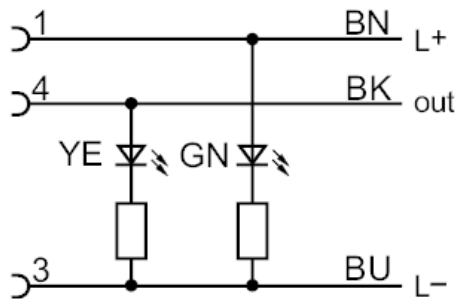

BN = Core colors : brown
BK = black
BU = blue