


E10974



Female cordset

ADOGF030MSS0008B03

Article no longer available - archive entry

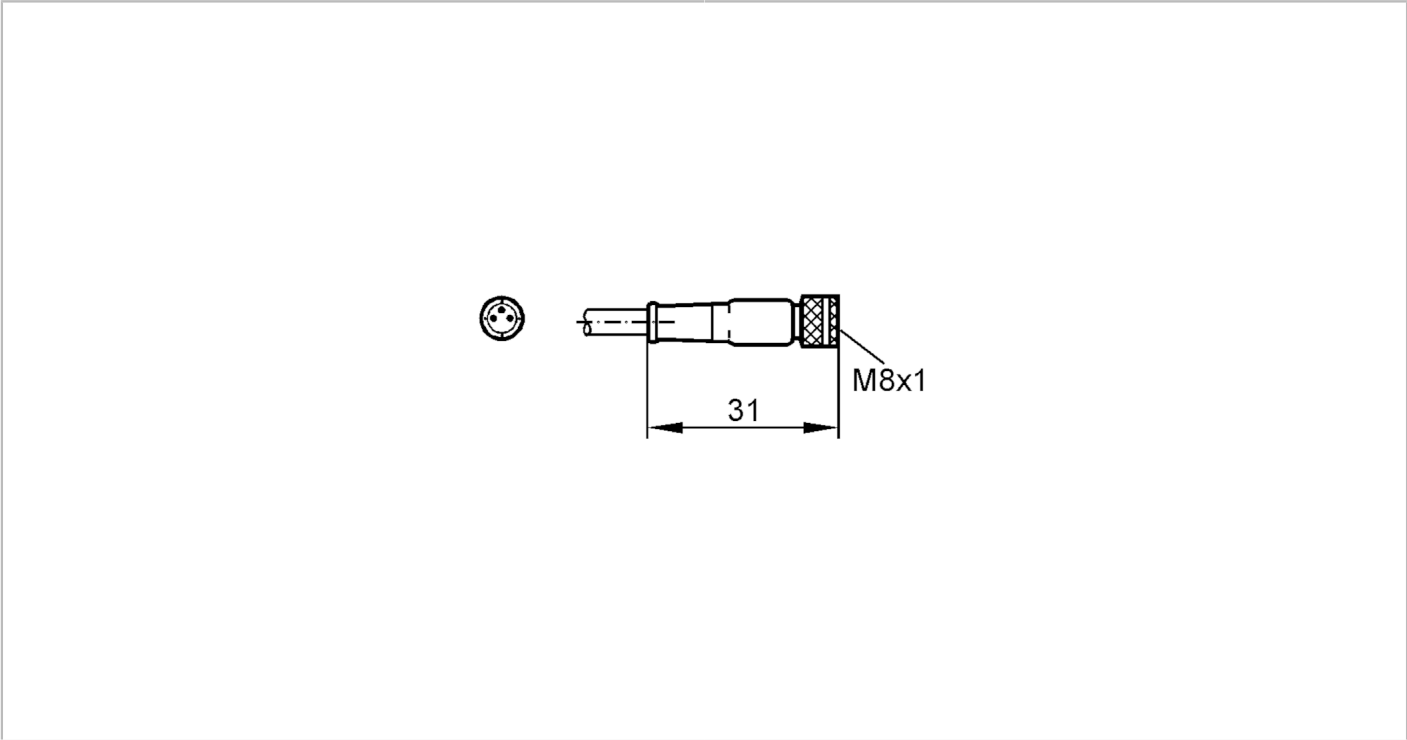

Electrical data		
Operating voltage	[M]	< 60 AC / < 75 DC
Protection class		III


Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data		
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated

Remarks		
Pack quantity		1 pcs.

Electrical connection		
Cable: 8 m, PUR, orange, Ø 5 mm; 3 x 0.34 mm²		

Electrical connection - Socket		
Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated		

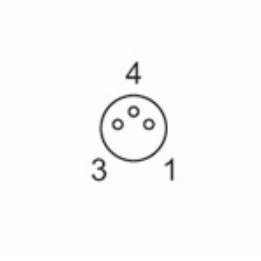


E10974



Female cordset

ADOGF030MSS0008B03

Connection

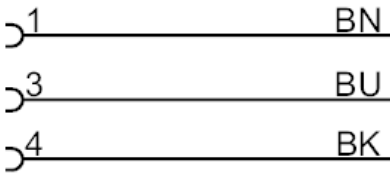

BN =	Core colors :
BK =	brown
BU =	black
	blue