



E10975



Female cordset

ADOGH080MSS0002A06

Article no longer available - archive entry

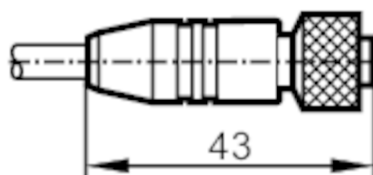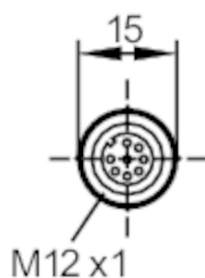

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load total	[A]	3

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	15 x 15 x 43
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E10975



Female cordset


ADOGH080MSS0002A06

Electrical connection

Cable: 2 m, PUR / PVC, black, Ø 6 mm; 6 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

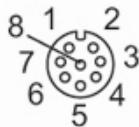

Connection

1	WH
2	GN
3	YE
4	GY
5	BN
7	BU

	Core colors :
BN =	brown
BU =	blue
GN =	green
GY =	grey
WH =	white
YE =	yellow