


E10977



Female cordset

ADOGH080MSS0010A06

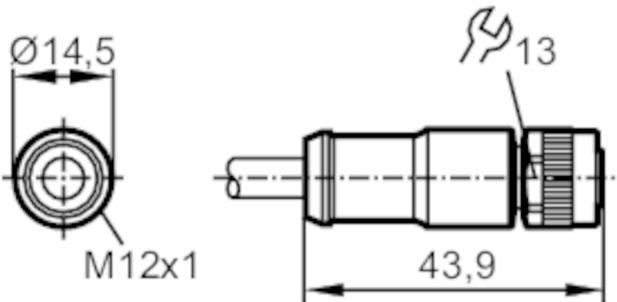

Electrical data		
Operating voltage	[V]	< 60 AC/DC
Max. current load total	[A]	2
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 68
Mechanical data		
Weight	[g]	468.7
Dimensions	[mm]	14.5 x 14.5 x 43.9
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10977



Female cordset


ADOGH080MSS0010A06

Electrical connection

Cable: 10 m, PUR, black, Ø 6 mm; 6 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: diecast zinc, nickel-plated

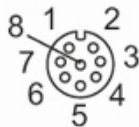

Connection

1	WH
2	GN
3	YE
4	GY
5	BN
7	BU

	Core colors :
BN =	brown
BU =	blue
GN =	green
GY =	grey
WH =	white
YE =	yellow