


E10978



Female cordset

ADOAH080MSS0002A06

Article no longer available - archive entry

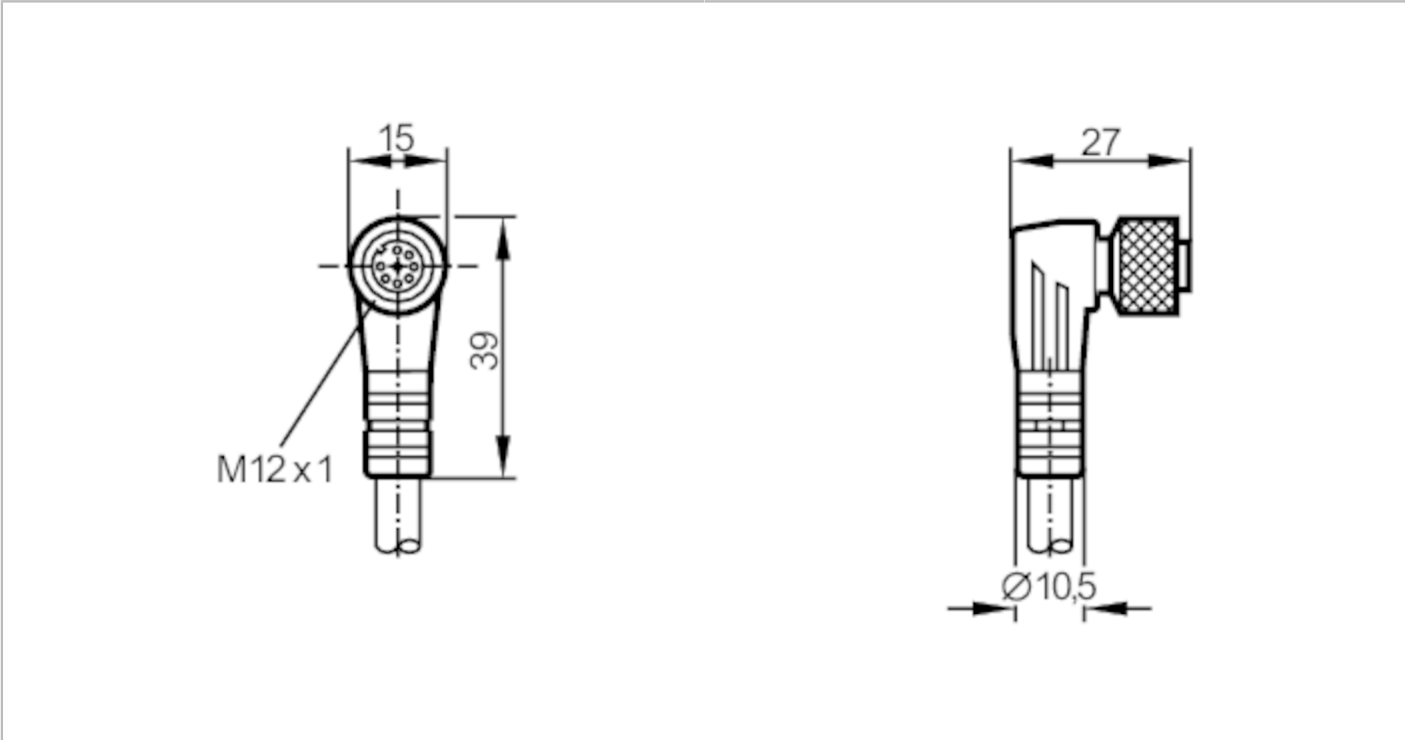


| Electrical data      |      |                      |
|----------------------|------|----------------------|
| Operating voltage    | [M]  | < 30 AC / < 36 DC    |
| Operating conditions |      |                      |
| Ambient temperature  | [°C] | -25...90             |
| Protection           |      | IP 67                |
| Mechanical data      |      |                      |
| Material             |      | TPU (urethane)       |
| Molded-body material |      | TPU (urethane)       |
| Material nut         |      | brass, nickel-plated |
| Remarks              |      |                      |
| Pack quantity        |      | 1 pcs.               |

Electrical connection

Cable: 2 m, PUR / PVC, black; 6 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

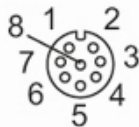


# E10978



## Female cordset

ADOAH080MSS0002A06

### Connection

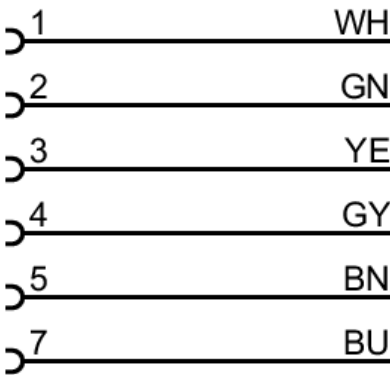

|      |               |
|------|---------------|
|      | Core colors : |
| BN = | brown         |
| BU = | blue          |
| GN = | green         |
| GY = | grey          |
| WH = | white         |
| YE = | yellow        |