

E10979




Female cordset

ADOAH080MSS0005A06

Article no longer available - archive entry

Alternative articles: E10980
When selecting an alternative article and accessories please note that technical data may differ!

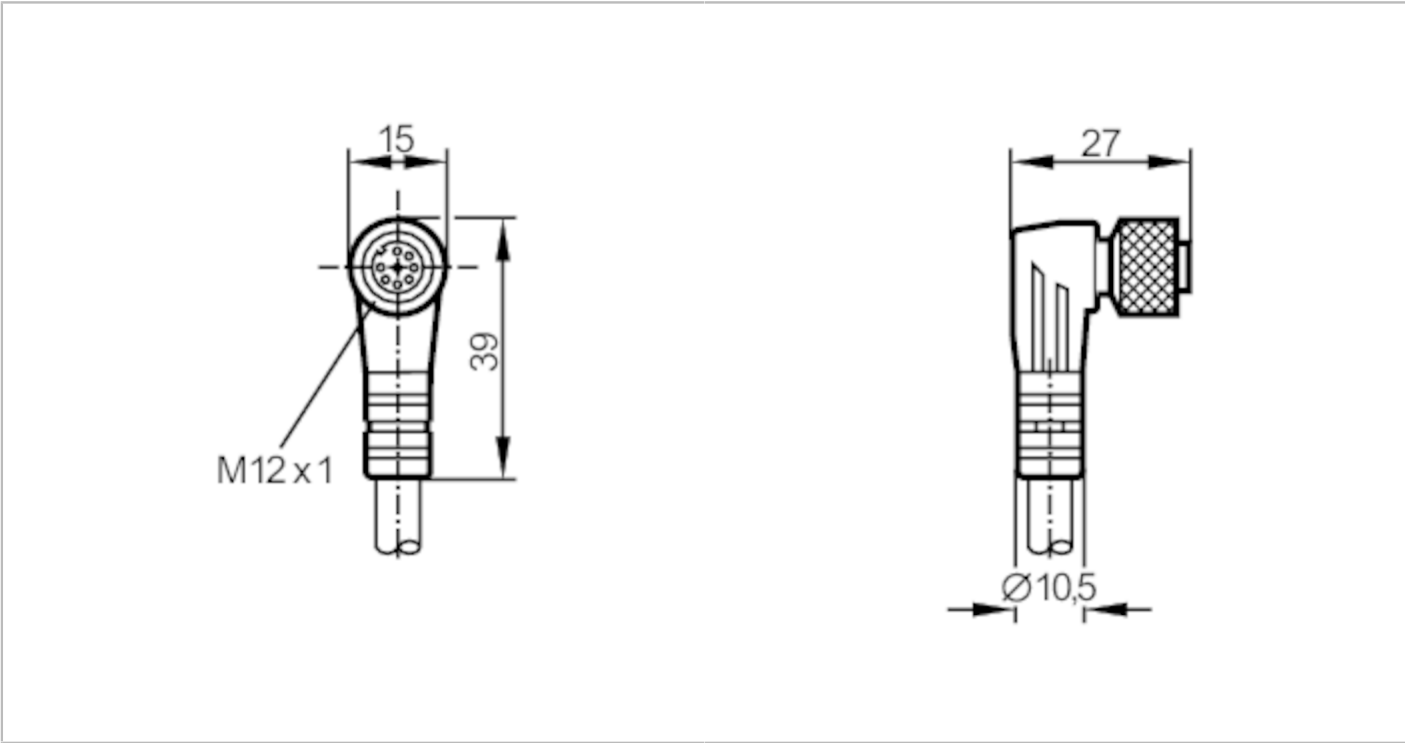

Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10979



Female cordset


ADOAH080MSS0005A06

Electrical connection

Cable: 5 m, PUR / PVC, black; 6 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

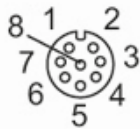

Connection

1	WH
2	GN
3	YE
4	GY
5	BN
7	BU

	Core colors :
BN =	brown
BU =	blue
GN =	green
GY =	grey
WH =	white
YE =	yellow