


E10981



Female wirable connectors

SDOGA030PLSFKPG

Article no longer available - archive entry

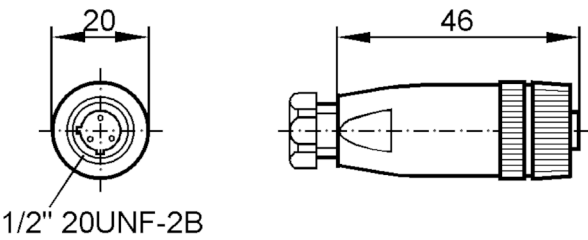

Electrical data

Operating voltage	[V]	10...55 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 67

Mechanical data

Dimensions	[mm]	20 x 20 x 46
Material		PA
Molded-body material		PA
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

terminals: ...0.75 mm²; Cable gland: PG 11

Electrical connection - Socket

Connector: 1 x 1/2", straight; coding: C; Moulded body: PA; Locking: brass, nickel-plated



E10981



Female wirable connectors

SDOGA030PLSFKPG

Connection

