

E10985




Male receptacle

ESTGH040MSS0,70E04 (PG13,5)

Article no longer available - archive entry

Alternative articles: E11295
When selecting an alternative article and accessories please note that technical data may differ!

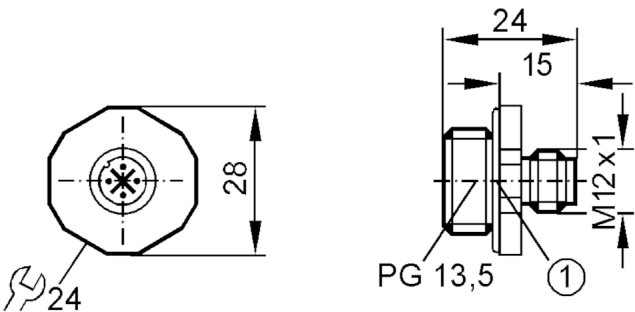

1 O-ring

Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Mounting thread		PG 13.5
Material		brass nickel-plated
Molded-body material		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10985



Male receptacle

ESTGH040MSS0,70E04 (PG13,5)

Electrical connection

Cable: 0.07 m, PVC; 4 x 0.34 mm²

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: brass, nickel-plated



Connection

1	BN
2	WH
3	BU
4	BK