




Connection cable

VDOGF030MSS0001H03STGH030MSS


Article no longer available - archive entry

Alternative articles: E11378
When selecting an alternative article and accessories please note that technical data may differ!

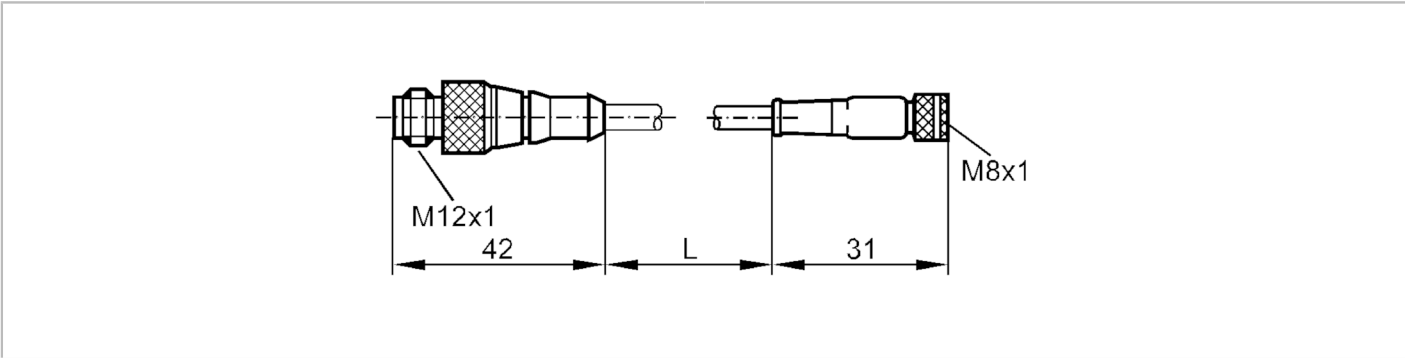

Application	
System	Halogen-free
Electrical data	
Operating voltage [V]	10...30 DC
Protection class	III
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 67
Mechanical data	
Material	TPU (urethane)
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection - plug	

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

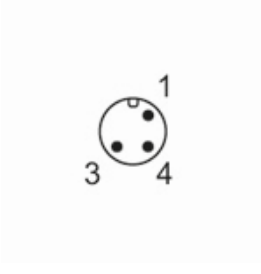

E10986



Connection cable

VDOGF030MSS0001H03STGH030MSS

Electrical connection

Cable: 1 m, PUR, Halogen-free, black, Ø 4.3 mm; 3 x 0.34 mm² (43 x Ø 0.1 mm)

Connection



Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

