


E10987



Connection cable

VDOGF030MSS0002H03STGH030MSS

Article no longer available - archive entry

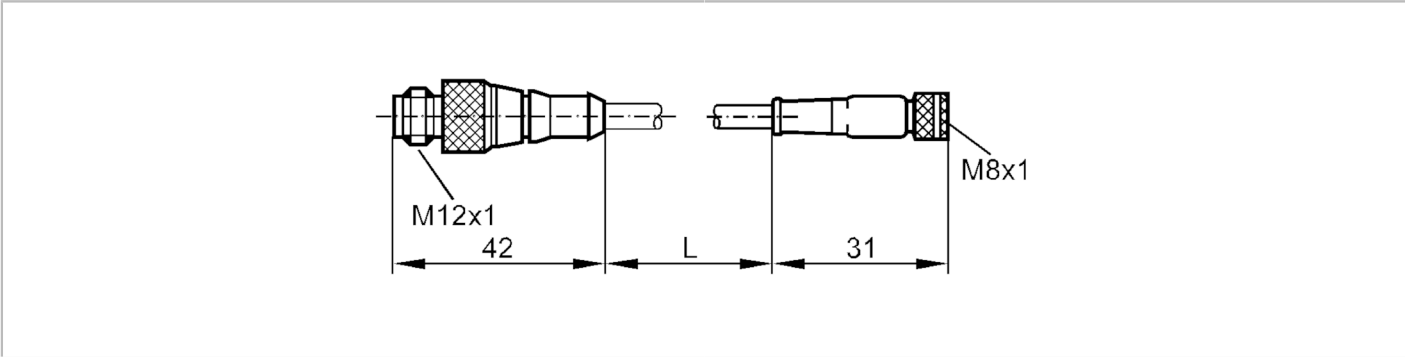

Application

System	Halogen-free
--------	--------------

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data


Material	TPU (urethane)
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

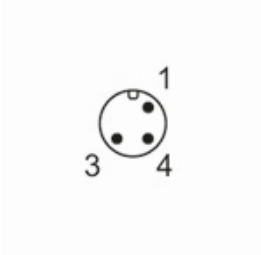

E10987




Connection cable

VDOGF030MSS0002H03STGH030MSS

Electrical connection

Cable: 2 m, PUR, Halogen-free, black, Ø 4.3 mm; 3 x 0.34 mm² (43 x Ø 0.1 mm)

Connection

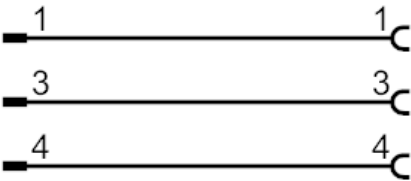

Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

