


E10989



Patchcords with valve plug

VVDAA041--S0005H03STGH030MSS

Article no longer available - archive entry

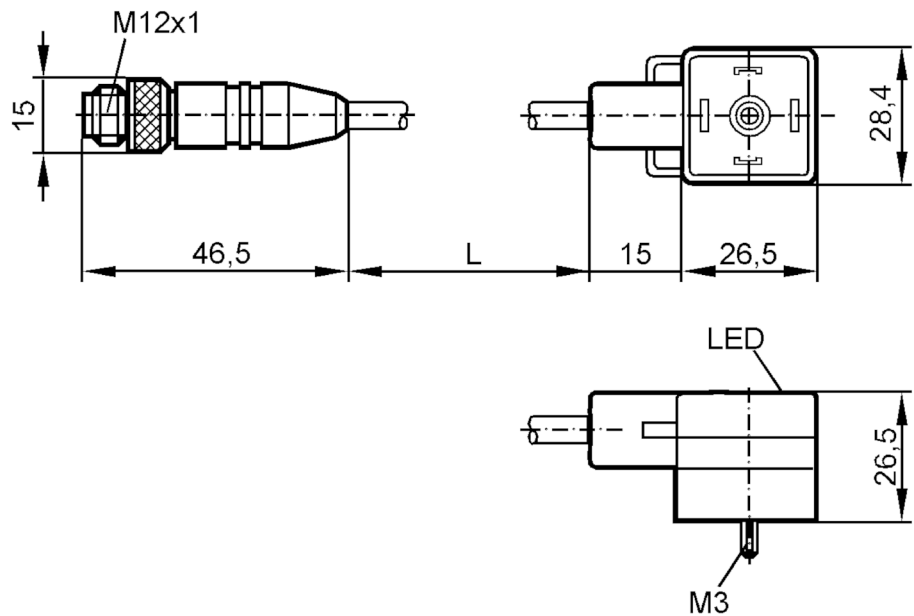

Application

System	Halogen-free
--------	--------------

Electrical data

Operating voltage [V]	< 24 AC/DC
Overvoltage protection	yes; (VDR)

Operating conditions

Ambient temperature [°C]	-25...90
Protection	IP 67

Mechanical data

Dimensions [mm]	15 x 15 x 46.5
Material	TPU (urethane)
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated

Accessories

Items supplied	screw
	panel for labelling

Remarks

Pack quantity	1 pcs.
---------------	--------

E10989



Patchcords with valve plug

VVDAA041--S0005H03STGH030MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Electrical connection

Cable: 5 m, PUR, Halogen-free; 3 x 0.5 mm²

Connection



Electrical connection - Socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

