

E10993




Patchcords with valve plug

VVDAA041--S00,6H03STGH030MSS

Article no longer available - archive entry

Alternative articles: E11417

When selecting an alternative article and accessories please note that technical data may differ!

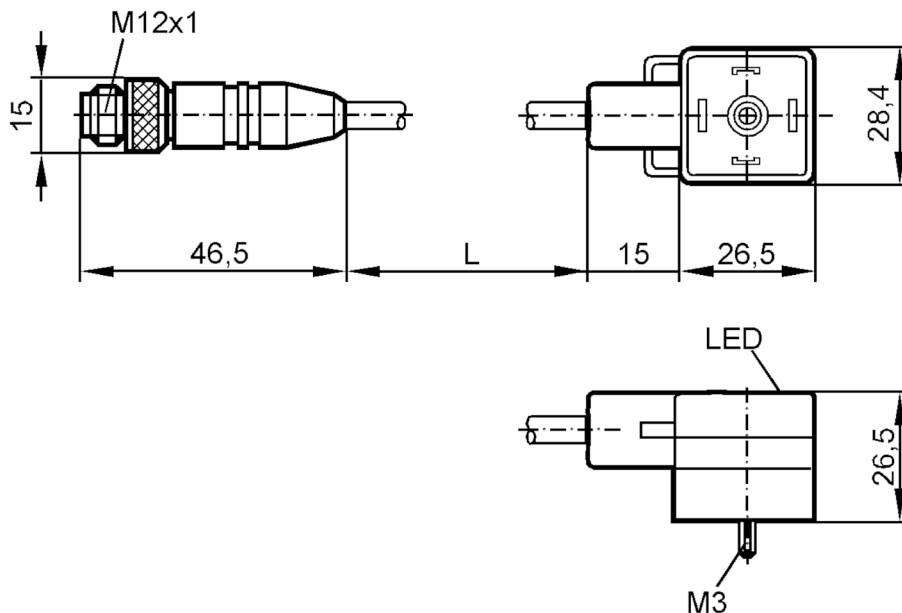

Application

System

Halogen-free

Electrical data

Operating voltage [V]

< 24 AC/DC

Overvoltage protection

yes; (VDR)

Operating conditions

Ambient temperature [°C]

-25...90

Protection

IP 67

Mechanical data

Dimensions [mm]

15 x 15 x 46.5

Material

TPU (urethane)

Molded-body material

TPU (urethane)

Material nut

brass, nickel-plated

Accessories

Items supplied

screw

panel for labelling

Remarks

Pack quantity

1 pcs.

E10993



Patchcords with valve plug

VVDAA041--S00,6H03STGH030MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Electrical connection

Cable: 0.6 m, PUR, Halogen-free; 3 x 0.5 mm²

Connection



Electrical connection - Socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

